

Worklight Wireless Charging

LED-375



CE IP65
RoHS IK07

Integrated

- 10W COB worklight
- 2W SMD top torch

Light Output

High quality light output in multiple modes

	LUMEN	RUN TIME	LUMEN	RUN TIME	LUMEN	RUN TIME
	HIGH		MEDIUM		LOW	
Worklight	1000	1.5 hours	500	2.5 hours	250	5 hours
Top Torch	120 lumen with a run time of 8 hours					

Sturdy Construction

- IP 65 Rated**
Protection against dust and effects of pressure jets from any direction
- IK 07 Rated**
Impact-proof with ABS body

Sturdy polycarbonate lens to withstand the toughest of jobs site conditions

Nylon hook with 360° rotating action for convenient placement of light

Swivelling Magnetic Base


The base can rotate upto 180° to adjust to the required angle



Strong magnet on the base makes it easy to mount onto any metallic surface for hands free use.

Dual Battery Charging Options

- Wireless charging using induction charging technology
- Can also be charged using micro USB cable provided with the light

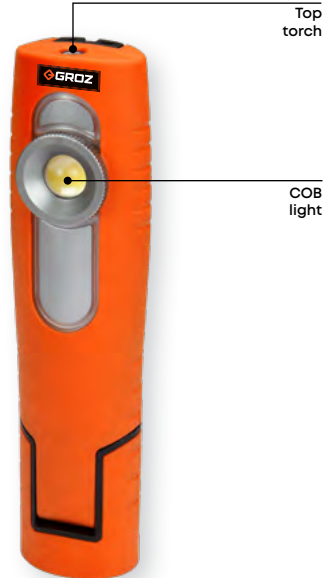

CAT NR.	SIZE	
	(INCH)	(MM)
LED/375	9 × 2 × 1-5/8	230 × 59 × 41.5

POWER SOURCE



3.7V 3350 mAh



SAFETY INFORMATION

- Follow workshop health & safety rules, regulations and conditions when using the 10W COB rechargeable inspection light.
- When not in use, COB rechargeable inspection light should be stored in a dry location to inhibit rust.
- During their period of use, accessories must be checked for wear, cracks and other damage, replace any damaged or worn parts.
- Use genuine parts only. Unauthorized parts may be dangerous and will void the warranty.
- Keep the COB rechargeable inspection light clean and in good working order for best and safest performance.
- DO NOT use the light in the immediate vicinity of inflammable materials or gases.
- DO NOT point the light directly in your own or any other person's or animal's eyes.
- DO NOT drop, throw or abuse the COB rechargeable inspection light.
- Eyes protection:** Wear a protective mask or protective eyewear.
- Check that the product has not suffered any damage during transport or storage. Clean and remove any dust or residual packing material.
- Read the instructions carefully before using COB rechargeable inspection light and keep them for further reference.

WARNING!

- DO NOT immerse COB rechargeable inspection light in water.
- DO NOT place COB rechargeable inspection light near a fire or any other source of intense heat.
- DO NOT attempt to open, disassemble, modify or service the light.
- DO NOT expose rechargeable COB rechargeable inspection light to temperatures above 40°C (104° F).
- DO NOT use COB rechargeable inspection light if you suspect that the batteries or the casing is damaged.

PACKAGE CONTENT

DESCRIPTION	QTY.
COB rechargeable inspection light	1
Docking station	1
Micro USB charger	1
O.I.P.M.	1

OPERATING INSTRUCTIONS

- Fully charge the battery before the first use. To charge
 - Connect the light to the power source with the help of micro USB charger provided with it.
 - Put the light on to the docking station and connect the docking station to the power source using micro USB charger provided with the light.
- While charging, the green LED charge indicators at the back of the light will blink continuously.
- When the battery is fully charged, all the indicator LEDs will turn green. Full charging takes about 5 hours.
- Press the power button located at the back of the light
 - Once for top torch "ON"
 - Twice for low intensity worklight "ON"
 - Three times for medium intensity worklight "ON"
 - Four times for high intensity worklight "ON"
 - Five times for switching "OFF" the light

MAINTENANCE

- Clean any dirt from the housing or the lens immediately, since it could cause overheating.
- If required, clean with a dry or slightly moist, clean cloth and a mild detergent. Do not use cleaners that contain abrasives or solvents.
- When not in use, COB rechargeable inspection light should be stored in a dry location.

TROUBLESHOOTING

PROBLEM	POSSIBLE CAUSE	CORRECTIVE ACTION
The COB rechargeable inspection light has low lumen output or does not work.	Low battery	Recharge the battery
If the COB rechargeable inspection light still doesn't work		Contact nearest authorized service dealer

DISPOSAL

The components or the used products must be given to companies that specialize in the disposal and recycling of industrial waste.



GROZ WARRANTY POLICY

Groz makes all efforts to ensure that its products meet the highest standards of quality and durability and warrants to the original purchaser its range of products for a period of 12 months from Groz Invoice date, against defects in materials and workmanship. If the Groz product is part of a set, only the portion that is defective is subject to this warranty.

This warranty does not apply to damage due directly or indirectly, to misuse, abuse, wear and tear, negligence or accident, repairs or alterations outside Groz plants, or to lack of maintenance. Groz shall in no event be liable for death, injuries to persons or property or for incidental, contingent, special or consequential damages arising from the use of its products. It is upto the user to determine suitability and safety of the product for their intended use, and the user assumes all risks and liability herewith.

In no event, shall Groz's liability exceed the invoiced cost of the product. In case of identification of defect covered under this warranty, the same must be notified in writing to Groz /Groz designated authorized service location. Proof of purchase date must accompany the complaint. Groz reserves the right to call back the faulty unit, all charges including transportation prepaid. On verification of the defect, the unit will be repaired or replaced with a new or reconditioned product or part of equal utility or a full refund given at Groz's discretion. The repaired /replaced units will be returned to the user freight prepaid, using most economical freight carrier. However if determined that the defect resulted from causes not within the scope of the warranty, then the cost of returning the product would be to buyer's account.

Groz Engineering Tools Pvt. Ltd. Groz Net Industries

Village Kherki Daula, National Highway-8,
Gurugram-122001, Haryana, INDIA

Tel +91.124.282.7700

E-Mail info@groz-tools.com

Url www.groz-tools.com

The GROZ name, GROZ logo and the  mark are trademarks of GROZ Engineering Tools Pvt. Ltd., India