

Headlamp

LED-250HP

High Powered Strip Light



500



4 HRS
at lowest intensity



4 HRS



230°



365 NM

Up your visibility game!

Engineered for versatility, this multi-mode headlamp lights up all directions over long distances

Integrated:

1. 5W COB wide angle Floodlight
2. 3W (2 x XPE) LED Spotlight
3. UV Light (365 Nm)

Light Output

Front COB LED panel for ultra wide-view flood beam giving 230° coverage and side spotlight for lighting up distances upto 45m/150'.

Single button controlled output in multiple modes

	1ST PRESS	2ND PRESS	3RD PRESS	4TH PRESS
	COB LIGHT		SPOTLIGHT	UV LIGHT 365 NM
	HIGH INTENSITY COB	LOW INTENSITY COB	HIGH INTENSITY	
LUMEN	500	160	135	-
RUN TIME	2 hours	4 hours	4 hours	-

Sensor Function

In-built sensor function for hands free ON/OFF of light. Wave to activate/deactivate light. Sensor can be activated in all modes

Durable Construction

Impact resistant construction: withstands falls upto 2m (6.5'). Highly Durable and stretchable headband.

Charging of battery


Type-C fast charging, protected by a rubber bezel.




Spot
UV



Hands Free Sensor:
Wave to activate/
deactivate light

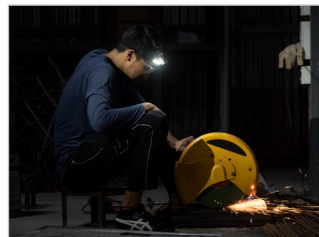

POWER SOURCE

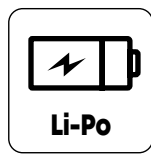

3.7V 1200 mAh

ORDERING INFORMATION

CAT NR.	ORD NR.	BOX QTY.
LED/250HP/UV	55125	40