


A RECHARGEABLE HEADLAMP WITH CLASS I, DIV 1 SAFETY RATINGS.

Three lighting modes cover a variety of tasks: spot for a focused beam, flood for soft area illumination that won't tire your eyes and spot/flood combo for even more light output.

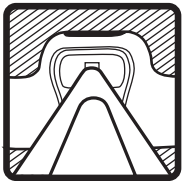

Spot/Flood Combo = 250 lumens

Features charge indicator
Red = charging
Green = charged



CHARGING



CHARGED


Battery charges in 4.5 hours

Multi-function push-button switch easy to use even with gloves

Adjustable elastic head strap



Lithium ion battery

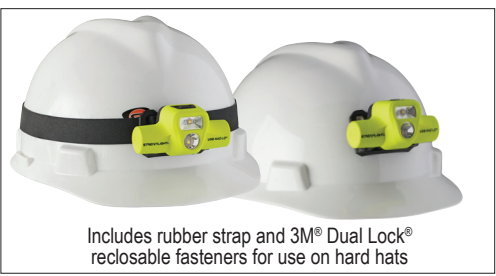


Spot and flood beams:
– Spot: 190 lumens; 2,000 candela; 89m beam; runs 7.5 hours
– Flood: 120 lumens; 90 candela; 19m beam; runs 13 hours
– Spot/flood combo: 250 lumens; runs 7 hours
Tilting head prevents neck fatigue
Tough, polycarbonate thermoplastic construction with elastomer button; Unbreakable polycarbonate lenses; recessed to prevent scratches
IP67 rated; dust-tight and waterproof to 1m for 30 minutes; 2m impact resistance tested

Class I, II, Division 1, Groups A, B, C, D, E, F, G; Class III; Class 1, Zone 0, Group IIC, T-Code: T4
4.1 oz (116.2 grams) with battery
Limited Lifetime Warranty Visit streamlight.com for full warranty information
#61460 - USB HAZ-LO - 120V AC, elastic headstrap, rubber hard hat strap, and 3M® Dual Lock® - Box - Yellow
#61462 - USB HAZ-LO - 230V AC, elastic headstrap, rubber hard hat strap, and 3M® Dual Lock® - Box - Yellow

3M® and Dual Lock® are registered trademarks of the 3M Company

USB HAZ-LO® HEADLAMP

RECHARGEABLE, INTRINSICALLY SAFE
MULTI-FUNCTION HEADLAMP

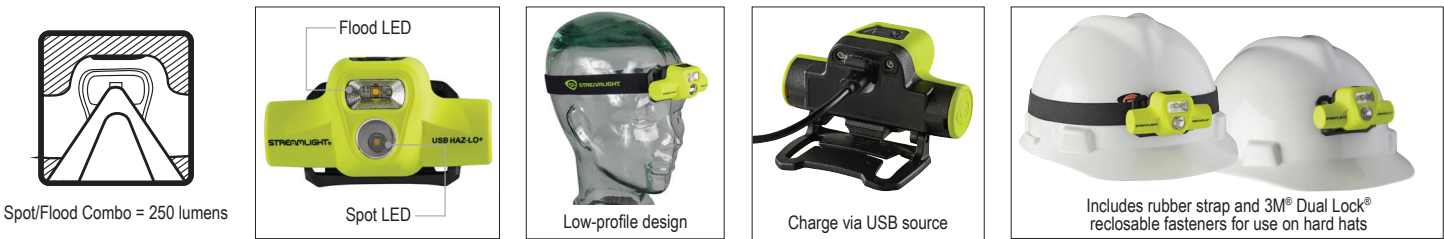

Material/Lens: Tough, polycarbonate thermoplastic construction with elastomer button. Unbreakable polycarbonate lenses; recessed to prevent scratches.

Dims/Weight: Height: 1.72 in. (4.36 cm) Width: 3.25 in. (8.25 cm) Depth: 1.75 in (4.45 cm)
Weight: 4.1 oz (116.2 grams) with battery

Output/Run Time: Spot and flood beams:

- Spot: 190 lumens; 2,000 candela; 89m beam; runs 7.5 hours
- Flood: 120 lumens; 90 candela; 19m beam; runs 13 hours
- Spot/flood combo: 250 lumens; runs 7 hours

Battery: One Streamlight #61461, 18650 li ion battery

Charging: Digital control circuit that prevents overcharge. Charge indication LED: Red - Charging; Green - Charged.
Fully recharges the battery in 4.5 hours with Streamlight AC charger. Charge time will vary when using the USB cord connected to a computer or other power source.

Features:

- Flood beam placement is designed to allow for shadow free operation when on a hard hat
- Micro USB charge port under rubber cover
- IP67 rated; dust-tight and waterproof to 1m for 30 minutes
- 2m impact resistance tested
- Class I, II, Division 1, Groups A, B, C, D, E, F, G; Class III; Class 1, Zone 0, Group IIC, T-Code: T4
- Tilting head prevents neck fatigue

Warranty: Limited Lifetime Warranty. Visit streamlight.com for full warranty information.

Approvals Class I, II, Division 1, Groups A, B, C, D, E, F, G; Class III; CL 1, Zn 0, IIC; T-Code: T4
Meets applicable European Community Directives
CEC Compliant

Item	UPC	Part #
USB HAZ-LO - 120V AC, elastic headstrap, rubber hard hat strap, and 3M® Dual Lock® - Box - Yellow	080926-61460-4	61460
USB HAZ-LO - 230V AC, elastic headstrap, rubber hard hat strap, and 3M® Dual Lock® - Box - Yellow	080926-61462-8	61462