


The high performance ProTac® 2.0 produces 2,000 lumens without sacrificing run time. Powered by the new SL-B50® battery pack that charges inside or outside of the light using a USB-C cord.



SL-B50® protected Li-Ion USB-rechargeable battery with on-board safety control. Recharges in 6 hours.

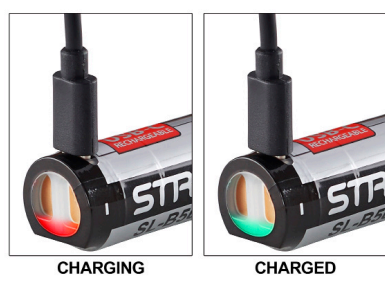

TEN-TAP® Programming: Choice of three operating modes: 1.) high/strobe/low; 2.) high only; 3.) low/medium/high
<ul style="list-style-type: none"> <li>- High: 2,000 lumens; 262m beam; runs 2.5 hours</li> <li>- Medium: 570 lumens; 142m beam; runs 4.5 hours</li> <li>- Low: 100 lumens; 60m beam; runs 25 hours</li> <li>- Strobe run time: runs 4 hours, 25 minutes</li> </ul>
Regulated power output provides consistent performance
Anti-roll face cap; serialized for positive identification

Durable anodized machined aircraft aluminum construction IP67; dust-tight and waterproof to 1m for 30 minutes; 2m impact resistance tested
6.10" (155mm); 8.25 oz (234g)
Limited Lifetime Warranty Visit <a href="http://streamlight.com">streamlight.com</a> for full warranty information
#89000 - ProTac 2.0 - SL-B50® battery pack, USB-C cord & nylon holster - Box