



2765

Headlamp

Pelican™ safety approved headlamps are designed for use in hazardous environments. It is not only Class I Div 1 approved but also is ultra compact and lightweight. Equipped with three uniquely positioned LEDs, It produces up to 155 lumens and provides up to 8 hours of run time. The Pelican 2765 offers multiple modes (high, low, downcast, flashing). The downcast LEDs provides illumination for pathway (offering greater safety), reading space (added convenience) and most appreciated by your counterparts whenever face to face interaction is in order (no more blinding your partner). Additionally, the Pelican 2765 offers a full time battery level indicator. You will now be able to monitor your battery level throughout the life of the batteries. It is available in two colors (yellow or black). Count on Pelican to bring you the best in lighting design and technology.

The new Pelican™ 2765 headlamp: Guiding you safely through the danger zone.

- Built Pelican tough
- Hands-free design
- Night vision friendly
- Comfortable Cloth Strap
- Safety Certified - Class I, Division I



DIMENSIONS

| | |
|---------------|----------------|
| Length | 2.25" (5.7 cm) |
|---------------|----------------|

MATERIALS

| | |
|---------------|--------------------|
| Body | Polycarbonate (PC) |
| O-Ring | Over-molded TPR |
| Lens | Polycarbonate (PC) |
| Shroud | Polycarbonate (PC) |

COLORS

| | |
|---|--|
|  Black |  High Visibility Yellow |
|---|--|

LIGHT SPECS

| | |
|------------------|-----|
| Lamp Type | LED |
|------------------|-----|

POWER

| | |
|--------------------------------|-----------------------------|
| Battery Size | AAA |
| Battery Type | Alkaline |
| Battery Quantity | 3 |
| Batteries Included | yes |
| Battery Level Indicator | Full-time battery indicator |
| Volts | 4.5v |

WEIGHT

| | |
|---------------------------------|----------------|
| Weight With Batteries | 3.4 oz (96 gr) |
| Weight Without Batteries | 2.1 oz (60 gr) |

SWITCH



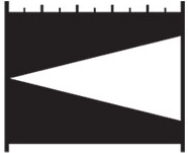



| | |
|--------------------|----------------------------------|
| Switch Type | Push Button |
| Light Modes | High / Low / Downcast / Flashing |

CERTIFICATIONS

| |
|----------------------------|
| Class I, Division 1 |
| IECEx ia |
| InMetro |

OTHER

| | |
|---------------------|---|
| Minimum Pack | 1 |
| Package Code | C |

| FL1 STANDARD | DOWNCAST | MAIN & DOWNCAST HIGH | MAIN & DOWNCAST LOW | MAIN HIGH |
|---|--------------|----------------------------|---------------------------|---------------|
|  | 34 LUMENS | 132 LUMENS | 78 LUMENS | 155 LUMENS |
|  | 14h 0mins | 5h 30mins | 8h 0mins | 6h 15mins |
|  | 10m | 68m | 46m | 81m |
|  | 23cd | 1157cd | 529cd | 1649cd |
|  | 1m | | | |
|  | IP54 | | | |

ACCESSORIES



2748

Strapless Headlamp Adapter

Pelican

23215 Early Ave • Torrance, CA 90505 USA • Phone: (310) 326-4700 • (800) 473-5422 • Fax: (310) 326-3311
sales@pelican.com • www.pelican.com

Document created on 05-12-24