



3325

Compact / Safety Certified / Tail Switch Design - All three are combined in the 3325 LED flashlight. The compact and lightweight design begins with the use of only 3 AA alkaline batteries and yet produces over 162 lumens of brilliant light. Safety certified for use in most volatile work environments. The rear mounted switch makes the 3325 a perfect match for any helmet mounted applications. The photoluminescent ("glow in the dark") shroud ensures you'll be able to locate your light even in the darkest of conditions. For added reliability, an IPX7 ingress protection level will protect the 3325 in the most severe weather conditions. Backed by Pelican's Lifetime Guarantee makes the 3325 a true value!

- 3 AA Batteries (Included)
- Glow-in-the-dark shroud
- Tail switch for easy one-handed operation
- Pelican Products, Inc.'s Lifetime Guarantee
- Ingress Protected IPX7
- Class I, Class II, Class III - Division 1 Safety Certified




DIMENSIONS

Length 6.06" (15.4 cm)

MATERIALS

Body EXL
O-Ring EPDM
Lens Polycarbonate (PC)
Shroud Photo luminescent Polycarbonate (PC)

COLORS

 High Visibility Yellow

LIGHT SPECS

Lamp Type LED

POWER

Battery Size AA
Battery Type Alkaline
Battery Quantity 3
Batteries Included yes
Volts 4.5v

WEIGHT

Weight With Batteries 6.1 oz (173 gr)
Weight Without Batteries 3.6 oz (102 gr)

SWITCH

Pelican

23215 Early Ave • Torrance, CA 90505 USA • Phone: (310) 326-4700 • (800) 473-5422 • Fax: (310) 326-3311
Push Button
Switch Type
Light Modes On / Off
sales@pelican.com • www.pelican.com



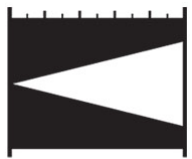


Document created on 10-04-22

CERTIFICATIONS

Class I, Division 1
IECEX ia
Class II, Division 1
Class III, Division 1

OTHER

Minimum Pack 1
Package Code C

FL1 STANDARD	HIGH
	171 LUMENS
	16h 0mins
	136m
	4558cd
	IPX7

ACCESSORIES