



非再用型

Non-Renewable Type

KT

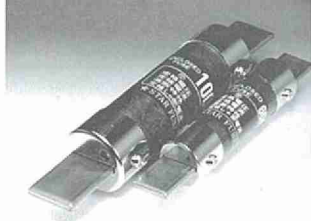

 エンクロヒューズ 刃形  
Enclosed Fuse



寸法 Size (mm)

定格電流(A) Ampere Rating	A	B	C	D	E	L
3・5・10・15・20・30	15	13	2	16	50	80
40・50・60	19	16	2.5	20	75	113
75・100	25	20	3.2	28	95	145
150・200	35	30	4.5	40	110	180
250・300・400	50	40	6.5	50	120	220
500・600	60	50	6.5	60	145	265

EA758ZV-21~26  
EA758ZV-27~29  
EA758ZV-30,31  
EA758ZV-32,33  
EA758ZV-34~36  
EA758ZV-37,38

寸法公差:電気用品安全法技術基準参照  
Dimensional tolerance: Refer to Technological Standard of  
Electrical Appliance and Material Safety Law

仕様 Spec (mm)

定格電圧(V) Voltage Rating	定格電流(A) Ampere Rating	遮断容量 Breaking Capacity	溶断特性 Electrical Characteristics	備考 Remarks
250	3・5・10・15・20・30	AC-2 (2500A)	B 種 Type B	消弧剤無 Non-arc extinguishing material
	40・50・60			
	75・100			
	150・200	AC-5 (5000A)		
	250・300・400			
	500・600			

認可規格  
Agency Approvals

特性表 Time-current characteristic curve

