


色でプラスのサイズの見分けが簡単!

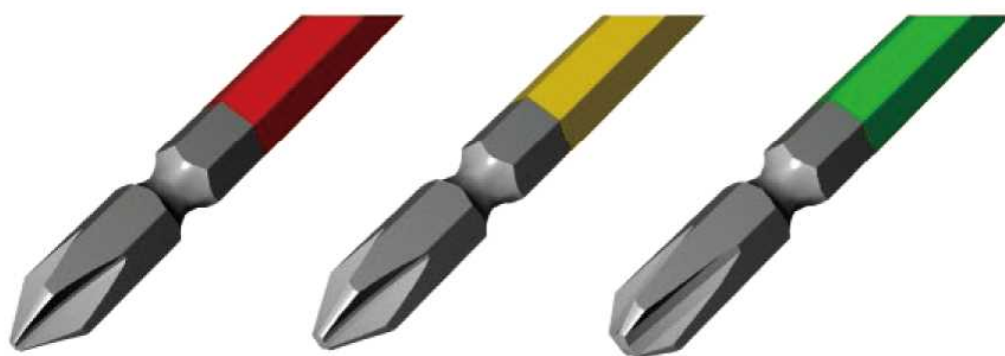

⊕ No.00

⊕ No.0



⊕ No.1

⊕ No.2

⊕ No.3





マグネット付 (ACD-00065のみマグネットなし)



ACM-1110



ACM-2110



ACM-3110



ACD-00065

マグネットなし



ACMD-0082



ACMM-5611









ACM5-1110



ACMD5-2100




ACM5-02

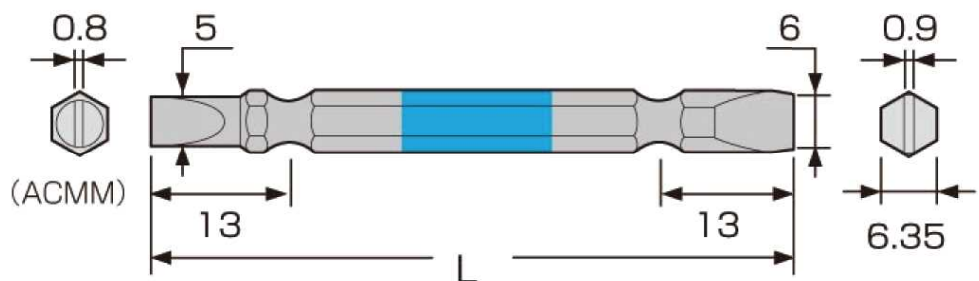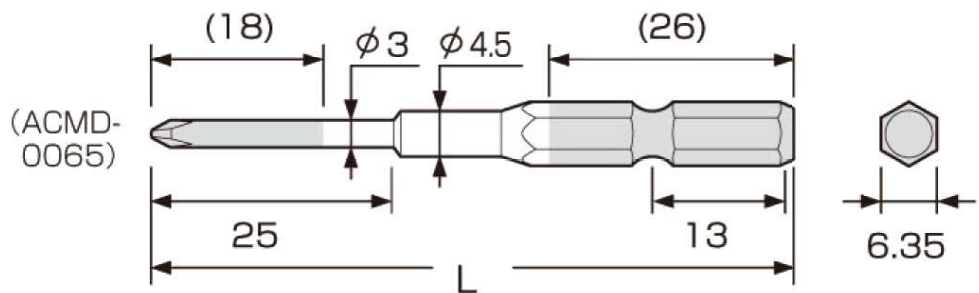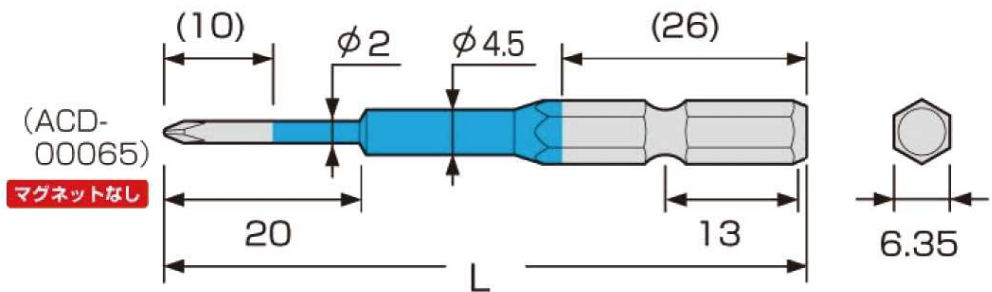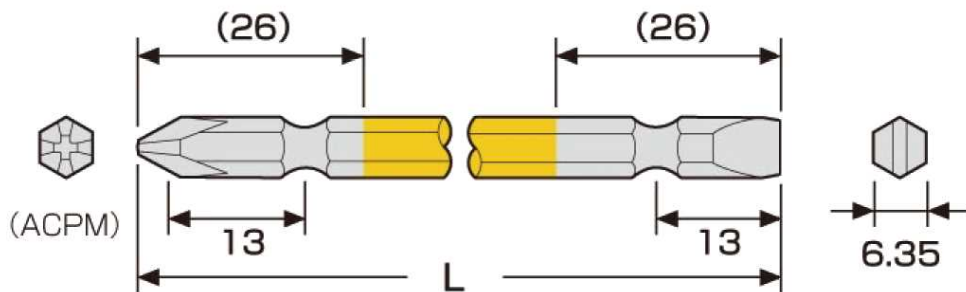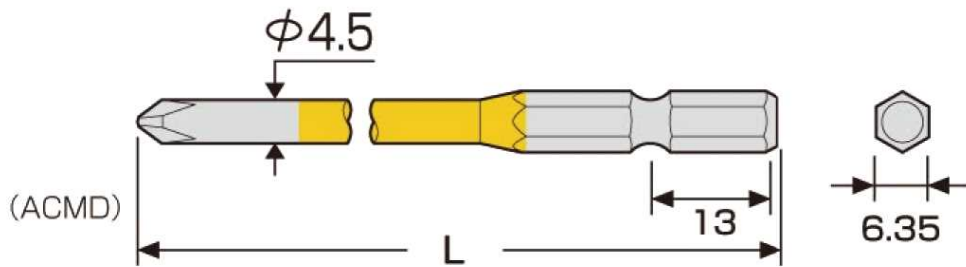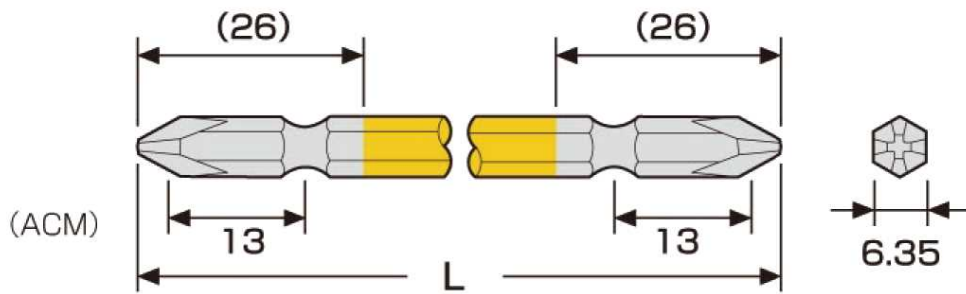

## ■ カラービット 1本組・2本組

No.	SIZE 刃先×全長 (L)	取付 本数	
ACM-1045	⊕ 1×45	2	
ACM-1065	⊕ 1×65	2	
ACM-1110	⊕ 1×110	2	EA813AA-12
ACM-2045	⊕ 2×45	2	
ACM-2065	⊕ 2×65	2	EA813AA-21
ACM-2085	⊕ 2×85	2	EA813AA-22A
ACM-2110	⊕ 2×110	2	EA813AA-22
ACM-2150	⊕ 2×150	2	EA813AA-23
ACM-2200	⊕ 2×200	1	EA813AA-24
ACM-2300	⊕ 2×300	1	EA813AA-25
ACM-3045	⊕ 3×45	2	
ACM-3065	⊕ 3×65	2	
ACM-3110	⊕ 3×110	2	EA813AA-32
ACM-3150	⊕ 3×150	2	EA813AA-33
ACM-3200	⊕ 3×200	1	EA813AA-34
ACM-3300	⊕ 3×300	1	EA813AA-35
ACPM-1065	⊕ 1×⊖5×65	2	
ACPM-2065	⊕ 2×⊖6×65	2	
ACPM-2110	⊕ 2×⊖6×110	2	
ACPM-2150	⊕ 2×⊖6×150	2	
ACD-00065	段付⊕00×65	2	EA813A-34
ACMD-0065	段付⊕0×65	2	EA813A-36
ACMD-0082	段付⊕0×82	2	EA813A-37
ACMD-0100	段付⊕0×100	2	EA813A-38
ACMD-1065	段付⊕1×65	2	EA813A-25A
ACMD-1100	段付⊕1×100	2	EA813A-26A
ACMD-2065	段付⊕2×65	2	EA813A-27A
ACMD-2082	段付⊕2×82	2	EA813A-28A
ACMD-2100	段付⊕2×100	2	EA813A-29A
ACMD-2150	段付⊕2×150	2	EA813A-30A
ACMD-2200	段付⊕2×200	1	EA813A-31A
ACMD-2300	段付⊕2×300	1	EA813A-32A
ACMM-5665	⊖5×⊖6×65	2	EA813AA-46
ACMM-5611	⊖5×⊖6×110	2	EA813AA-47

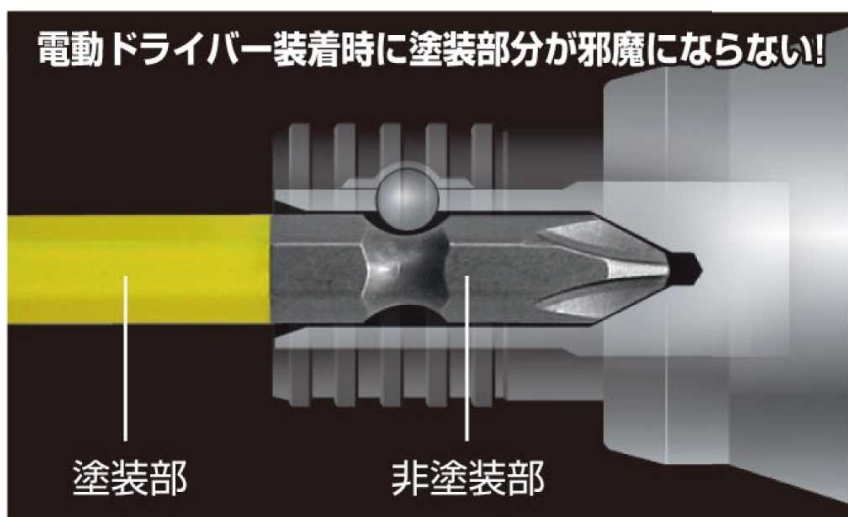

### ■ 部分的耐熱カラー塗装

ビット両端部は（先端・後端）は非塗装ですので先端精度は抜群です。