

EA815ZY-42~-46、ZY-52~-56 ダウントランス(静電シールド付)



BL型/ラグ端子式

42 43 44

52 53 54




SL型/ラグ端子式

45 55



P型/端子台式

46 56

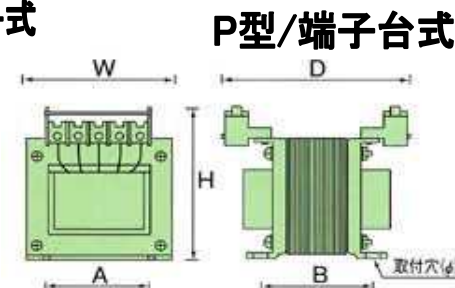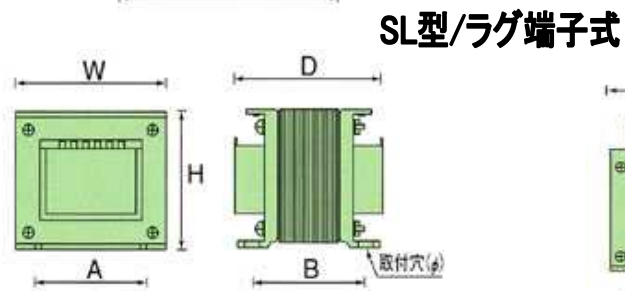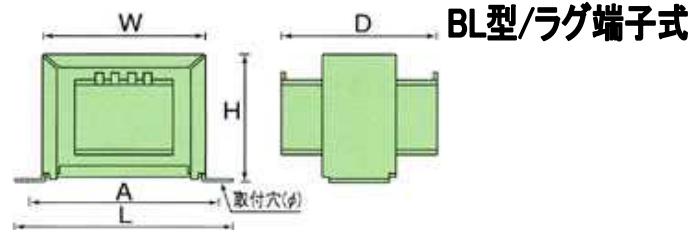

品番	仕様				端子ねじ	寸法(mm)						重量kg	取付穴φ	
	一次電圧	二次電圧(AC)	電流	形状		W	H	D	A	B	L			
EA815ZY-42	110V-100V-0-E	24V-20V-15V-12V-6V-0	0.5A	BL	-	60	52	48	72		84	0.46	4.5X7.5	廃番
EA815ZY-43	110V-100V-0-E	24V-20V-15V-12V-6V-0	1A	BL	-	70	60	58	80		91	0.8	4.5X6.5	
EA815ZY-44	110V-100V-0-E	24V-20V-15V-12V-6V-0	2A	BL	-	80	70	65	93		105	1.2	4.5X6.5	廃番
EA815ZY-45	110V-100V-0-E	24V-20V-15V-12V-6V-0	3A	SL	-	86	75	85	62	68		2	4.5X10	
EA815ZY-46	110V-100V-0-E	24V-20V-15V-12V-6V-0	5A	P	M4	105	107	104	66	65		3	5.5X10	
EA815ZY-52	220V-200V-0-E	24V-20V-15V-12V-6V-0	0.5A	BL	-	60	52	48	72		84	0.46	4X7.5	
EA815ZY-53	220V-200V-0-E	24V-20V-15V-12V-6V-0	1A	BL	-	70	60	58	80		91	0.8	4.5X6.5	
EA815ZY-54	220V-200V-0-E	24V-20V-15V-12V-6V-0	2A	BL	-	80	70	65	93		105	1.2	4.5X6.5	
EA815ZY-55	220V-200V-0-E	24V-20V-15V-12V-6V-0	3A	SL	-	86	75	85	62	68		2	4.5X10	
EA815ZY-56	220V-200V-0-E	24V-20V-15V-12V-6V-0	5A	P	M4	105	107	104	66	65		3	5.5X10	廃番

●単相複巻き

●静電シールド付