


ドリルチャックアーバー

EA817CE-1～-23

(ドリルチャックアーバー)

特長

○ 高周波焼入が必要部分には適切に施してありますので耐久性は抜群です。

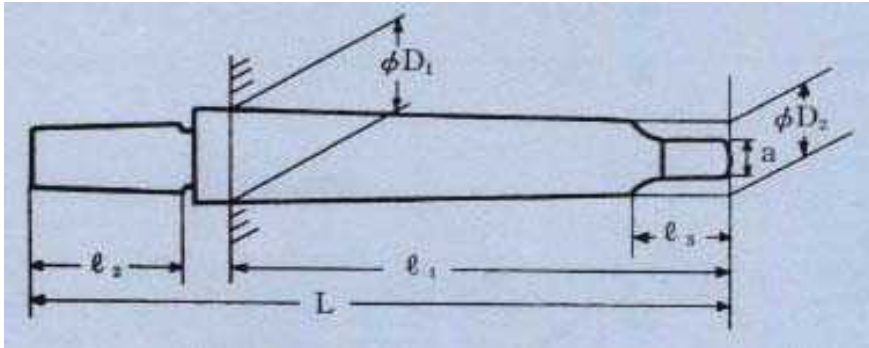

※赤線は廃番です

型番 Model No.		L	L1	L2	L3	D1	D2	a	重量(kg)
EA817CE-1	1×1	93	62	21	13.5	12.065	9	5.2	0.07
EA817CE-2	1×2	108	75	21	16	17.78	14	6.3	0.15
EA817CE-3	1×3	127	94	21	20	23.825	19.1	7.9	0.3
EA817CE-11	2×1	98	62	26	13.5	12.065	9	5.2	0.08
EA817CE-12	2×2	112	75	26	16	17.78	14	6.3	0.17
EA817CE-13	2×3	131	94	26	20	23.825	19.1	7.9	0.33
EA817CE-14	2×4	156	117.5	26	24	31.267	25.2	11.9	0.66
EA817CE-21	6×2	118	75	32	16	17.78	14	6.3	0.2
EA817CE-22	6×3	137	94	32	20	23.825	19.1	7.9	0.35
EA817CE-23	6×4	162	117.5	32	24	31.267	25.2	11.9	0.69

