


EA819DF-31～58 **すべて取扱中止です**
 ダイヤモンドバー (3mm軸)

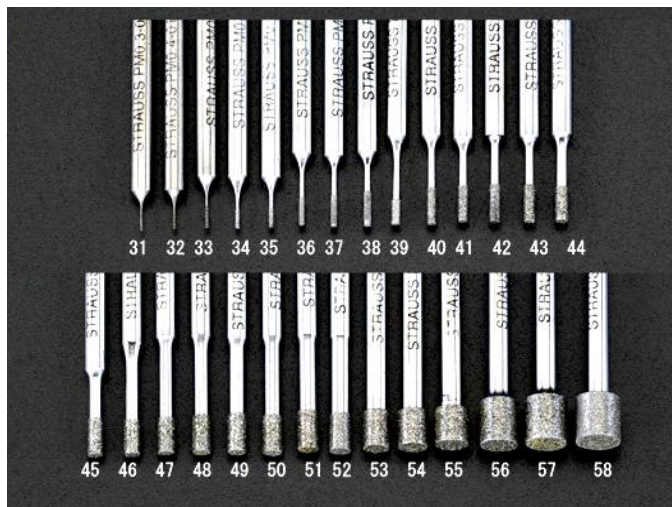

切れ味がよく、ダイヤが長持ちします！！

＜仕様＞

●形状…シリンダー ●軸径…3mm

●砥粒…ダイヤモンド

品番	刃径(mm)	刃長(mm)	全長(mm)	粒度
EA819DF-31	0.3	2.0	40	#400
EA819DF-32	0.4			
EA819DF-33	0.5	3.0	50	#325
EA819DF-34	0.6			
EA819DF-35	0.7			
EA819DF-36	0.8	4.0		
EA819DF-37	0.9			
EA819DF-38	1.0	5.0	55	#200
EA819DF-39	1.2			
EA819DF-40	1.3			
EA819DF-41	1.4			
EA819DF-42	1.5			
EA819DF-43	1.6			#140
EA819DF-44	1.8			
EA819DF-45	2.0			
EA819DF-46	2.2			
EA819DF-47	2.3			
EA819DF-48	2.4			
EA819DF-49	2.5			
EA819DF-50	2.6			
EA819DF-51	2.8			
EA819DF-52	3.0			
EA819DF-53	3.5			
EA819DF-54	4.0			
EA819DF-55	4.5			
EA819DF-56	5.0	6.0		
EA819DF-57	5.5			
EA819DF-58	6.0			