
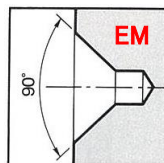


超硬センタードリル EA824EL-0.5~6、EM-0.5~6

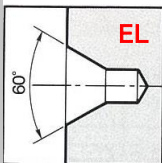

- 超硬付き
- 高硬度材料に
- 精度のよい機械向け
- 耐摩耗性に優れ、面粗度も向上します。

品番	角度	サイズ(mm)				
		先端径	胴径	全長	刃長(/)	
EA824EL-0.5	60°	0.5	3.0	31.0	0.6	
EA824EL-0.7		0.7	3.5	36.0	0.9	
EA824EL-1		1.0	4.0		1.2	
EA824EL-1.5		1.5	5.0	42.0	1.9	
EA824EL-2		2.0	6.0	47.0	2.5	
EA824EL-2.5		2.5	8.0	53.0	3.1	
EA824EL-3		3.0			3.7	
EA824EL-4		4.0	10.0	58.0	5.0	
EA824EL-4B		5.0	12.0	69.0		6.3
EA824EL-5			6.0	18.0	95.0	7.5
EA824EL-6						

品番	角度	サイズ(mm)				
		先端径	胴径	全長	刃長(/)	
EA824EM-0.5	90°	0.5	3.0	31.0	0.6	
EA824EM-0.7		0.7	3.5	36.0	0.9	
EA824EM-1		1.0	4.0		1.2	
EA824EM-1.5		1.5	5.0	42.0	1.9	
EA824EM-2		2.0	6.0	47.0	2.5	
EA824EM-2.5		2.5	8.0	53.0	3.1	
EA824EM-3		3.0			3.7	
EA824EM-4		4.0	10.0	58.0	5.0	
EA824EM-4B		5.0	12.0	69.0		6.3
EA824EM-5			6.0	18.0	95.0	7.5
EA824EM-6						

—:取扱中止