
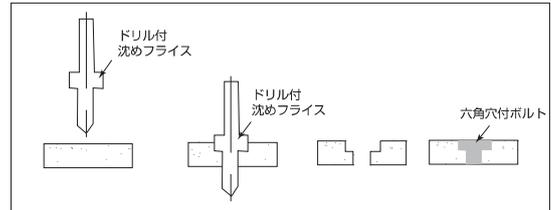


# DCB ドリル付沈めフライス (六角穴付ボルト用)

SINCE 1935  
F.K.D.®

## DCB Cap Screw Counterbores with Drill

材質=HSS(SKH51) 刃数=2枚 リード角=右振り25°  
 外径公差=0~+0.2 ドリル径公差=0~-0.05

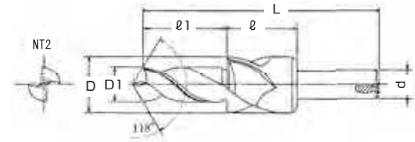

| 型番         | 呼称 | ドリル径(D1) | ドリル長(ℓ1) | 外径(D) | (ℓ) | 全長(L) | シャンク径(d) |
|------------|----|----------|----------|-------|-----|-------|----------|
| EA824MF-3  | 3  | 3.5      | 15       | 5.9   | 7   | 50    | 6        |
| EA824MF-4  | 4  | 4.5      | 15       | 7.4   | 9   | 55    | 6        |
| EA824MF-5  | 5  | 5.5      | 20       | 8.9   | 12  | 63    | 8        |
| EA824MF-6  | 6  | 6.5      | 25       | 10.4  | 13  | 70    | 8        |
| EA824MF-8  | 8  | 8.5      | 30       | 13.4  | 16  | 79    | 10       |
| EA824MF-10 | 10 | 10.6     | 35       | 16.8  | 20  | 87    | 12       |
| EA824MF-12 | 12 | 12.7     | 35       | 18.8  | 23  | 92    | 12       |