


6SDP 直径

単位:mm

	直径	溝長	全長	JANコード 4991893
	1.0	12	69	139884
	1.2	16	73	139891
EA824PG-1.5	1.5	18	75	139907
	1.6	20	76	139914
	1.8	22	76	139921
EA824PG-2.0	2.0	24	79	121360
	2.1	24	79	121377
	2.2	27	83	121384
EA824PG-2.3	2.3	27	83	121391
EA824PG-2.4	2.4	30	87	121407
EA824PG-2.5	2.5	30	87	121414
	2.6	30	87	121421
EA824PG-2.7	2.7	33	91	121438
EA824PG-2.8	2.8	33	91	121445
	2.9	33	91	121452
EA824PG-3.0	3.0	33	91	121469
	3.1	36	95	121476
EA824PG-3.2	3.2	36	95	121483
EA824PG-3.3	3.3	36	95	121490
EA824PG-3.4	3.4	39	100	121506
EA824PG-3.5	3.5	39	100	121513
EA824PG-3.6	3.6	39	100	121520
EA824PG-3.7	3.7	39	100	121537
EA824PG-3.8	3.8	43	105	121544
EA824PG-3.9	3.9	43	105	121551
EA824PG-4.0	4.0	43	105	121568
EA824PG-4.1	4.1	43	105	121575
EA824PG-4.2	4.2	43	105	121582
EA824PG-4.3	4.3	47	110	121599
	4.4	47	110	121605
EA824PG-4.5	4.5	47	110	121612
EA824PG-4.6	4.6	47	110	121629
	4.7	47	110	121636
EA824PG-4.8	4.8	52	116	121643
	4.9	52	116	121650
EA824PG-5.0	5.0	52	116	121667
EA824PG-5.2	5.2	52	116	121674
EA824PG-5.5	5.5	57	123	121681
EA824PG-6.0	6.0	57	123	121698
EA824PG-6.5	6.5	45	105	139600
EA824PG-7.0	7.0	45	105	139617
	7.5	45	105	139624
EA824PG-8.0	8.0	45	105	139631
EA824PG-8.5	8.5	45	105	139648
EA824PG-9.0	9.0	45	105	139655
EA824PG-9.5	9.5	45	105	139662
EA824PG-10	10.0	50	105	139679
EA824PG-10.5	10.5	50	105	139686
EA824PG-11	11.0	50	105	139693
EA824PG-11.5	11.5	50	105	139709
EA824PG-12	12.0	50	105	139716
EA824PG-12.5	12.5	50	105	139723
EA824PG-13	13.0	50	105	139730

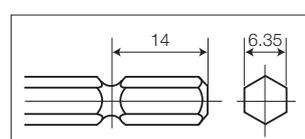

六角軸シャンク

6SD3P

鉄工用六角軸ドリル 3本入



充電ドライバーに
ワンタッチで着脱

○3本入包装。

6SD3P 直径

単位:mm

直径	溝長	全長	JANコード 4991893
2.0	24	79	139983
2.5	30	87	139990
2.8	33	91	140002
3.0	33	91	140019
3.2	36	95	140026
3.3	36	95	140033
3.5	39	100	140040
3.8	43	105	140057
4.0	43	105	140064
4.2	43	105	140071
4.5	47	110	140088
5.0	52	116	140095
6.0	57	123	140101

6LSDP

鉄工用ロングリーチ六角軸ドリル



深い位置の穴あけに
最適です。

○1本入包装。

6LSDP 直径

単位:mm

直径	溝長	全長	JANコード 4991893
2.0	24	180	141726
2.5	30	180	141733
2.8	33	180	141801
3.0	33	180	141740
3.2	36	180	141818
3.5	39	180	141757
3.8	43	180	141825
4.0	43	180	141764
4.2	43	180	141832
4.5	47	180	141771
5.0	52	180	141788
5.5	57	180	141849
6.0	57	180	141795

