

ジェットタップ(ポイントタップ) 通り穴用

Jet Screw Taps(Point Taps) For Through Holes

HSSE

Ox



食付き部


5P




単位:mm

J形

Type A

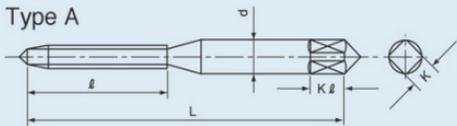

Type C

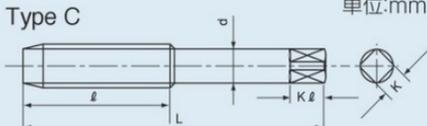

J形 ジェットタップ

Jet Screw Taps J-Type

単位:円(JPY)

呼び	品番	形状 Type	精度	形状寸法							溝数	定価	
				L	ℓ	d	Ln	Dn	K	kℓ			
EA829EV-540	M4×0.7	HJ040IJ	A	H2	52	20	5	-	-	4	7	3	1,360
EA829EV-550	M5×0.8	HJ050KJ	A	H2	60	22	5.5	-	-	4.5	7	3	1,390
EA829EV-560	M6×1.0	HJ060MJ	A	H2	61	24	6	-	-	4.5	7	3	1,510
EA829EV-580	M8×1.25	HJ080NJ	C	H3	70	30	6.2	-	-	5	8	3	2,180
EA829EV-610	M10×1.5	HJ100OJ	C	H3	75	32	7	-	-	5.5	8	3	2,760
EA829EV-612	M12×1.75	HJ120PJ	C	H3	82	38	8.5	-	-	6.5	9	3	3,860

推奨被削材	構造用鋼 SS400	低炭素鋼 S15C	高炭素鋼 S55C	合金鋼 SCM	調質鋼 HRC25~35	調質鋼 HRC35~40	ステンレス SUS	鋳鉄 FC	ダクタイル鋳鉄 FCD	アルミニウム合金 AL	銅合金 Cu	チタン合金 Ti
	◎	◎		○					△	△	△	