

ジェットタップ(ポイントタップ) 通り穴用




Jet Screw Taps(Point Taps) For Through Holes

HSSE

Ox



食付き部
5P

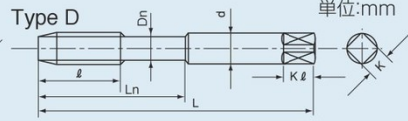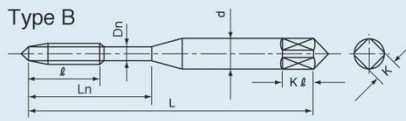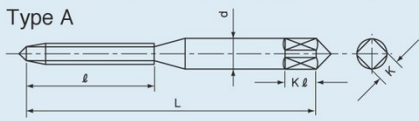

単位:mm

タップ・ダイス

メートルねじ(Metric Thread)

単位:円(JPY)

呼び	品番	形状 Type	精度	形状寸法							溝数	定価
				L	l	d	Ln	Dn	K	k		
M2×0.4	HJ020E	A	H1	40	11	3	-	-	2.5	5	3	1,980
M2.3×0.4	HJ023E	A	H1	42	11	3	-	-	2.5	5	3	1,980
M2.5×0.45	HJ025F	A	H2	44	13	3	-	-	2.5	5	3	1,980
M2.6×0.45	HJ026F	A	H2	44	13	3	-	-	2.5	5	3	1,810
3M×0.6(旧JIS)	HJ030H	A	H2	46	18	4	-	-	3.2	6	3	1,410
M3×0.5	HJ030G	A	H2	46	18	4	-	-	3.2	6	3	1,410
M3×0.35	HJ030D	A	H2	46	11	4	-	-	3.2	6	3	2,120
M3.5×0.6	HJ035H	A	H2	48	18	4	-	-	3.2	6	3	1,560
4M×0.75(旧JIS)	HJ040J	B	H2	52	13	5	20	3.3	4	7	3	1,360
M4×0.7	HJ040I	B	H2	52	13	5	20	3.2	4	7	3	1,360
M4×0.5	HJ040G	B	H2	52	13	5	20	3.3	4	7	3	1,880
M4.5×0.75	HJ045J	B	H2	55	13	5	20	3.6	4	7	3	1,780
5M×0.9(旧JIS)	HJ050L	B	H2	60	16	5.5	23	4.05	4.5	7	3	1,390
M5×0.8	HJ050K	B	H2	60	16	5.5	24	4.05	4.5	7	3	1,390
M5×0.5	HJ050G	B	H2	52	16	5.5	24	4.2	4.5	7	3	1,900
M6×1.0	HJ060M	B	H2	61	19	6	27	4.8	4.5	7	3	1,510
M6×0.75	HJ060J	B	H2	61	19	6	27	4.85	4.5	7	3	1,980
M7×1.0	HJ070M	B	H2	65	19	6.2	28	5.7	5	8	3	1,950
M8×1.25	HJ080N	D	H3	70	22	6.2	30	5.9	5	8	3	2,180
M8×0.75	HJ080J	D	H2	62	19	6.2	27	5.9	5	8	3	2,950
M8×1.0	HJ080M	D	H3	70	20	6.2	28	5.9	5	8	3	2,540
M9×1.25	HJ090N	D	H3	72	22	7	30	6.7	5.5	8	3	2,720
M10×1.5	HJ100O	D	H3	75	24	7	34	6.7	5.5	8	3	2,760
M10×1.25	HJ100N	D	H3	75	24	7	34	6.7	5.5	8	3	2,760
M10×1.0	HJ100M	D	H3	70	20	7	30	6.7	5.5	8	3	3,490
M10×0.75	HJ100J	D	H3	62	19	7	27	6.7	5.5	8	3	3,960
M12×1.75	HJ120P	D	H3	82	29	8.5	41	8.2	6.5	9	3	3,860
M12×1.5	HJ120O	D	H3	82	29	8.5	39	8.2	6.5	9	3	3,860
M12×1.25	HJ120N	D	H3	80	29	8.5	39	8.2	6.5	9	3	3,860
M12×1.0	HJ120M	D	H3	70	20	8.5	28	8.2	6.5	9	3	4,660
M14×2.0	HJ140Q	D	H4	88	30	10.5	44	10.1	8	11	3	5,290
M14×1.5	HJ140O	D	H3	88	30	10.5	44	10.1	8	11	3	5,290
M14×1.25	HJ140N	D	H3	88	30	10.5	44	10.1	8	11	3	6,120
M14×1.0	HJ140M	D	H3	70	22	10.5	30	10.1	8	11	3	6,320
M16×2.0	HJ160Q	D	H4	95	32	12.5	47	12.1	10	13	3	7,040
M16×1.5	HJ160O	D	H3	95	32	12.5	47	12.1	10	13	3	7,040
M16×1.0	HJ160M	D	H3	75	24	12.5	32	12.1	10	13	3	8,260
M18×2.5	HJ180R	D	H4	100	37	14	52	13.5	11	14	3	9,670
M18×2.0	HJ180Q	D	H4	95	37	14	52	13.5	11	14	3	10,400
M18×1.5	HJ180O	D	H4	95	37	14	52	13.5	11	14	3	9,670
M18×1.0	HJ180M	D	H3	80	24	14	34	13.5	11	14	3	11,820
M20×2.5	HJ200R	D	H4	105	37	15	54	14.5	12	15	3	12,430
M20×2.0	HJ200Q	D	H4	95	37	15	52	14.5	12	15	4	15,130
M20×1.5	HJ200O	D	H4	95	37	15	52	14.5	12	15	4	12,430
M20×1.0	HJ200M	D	H3	80	24	15	34	14.5	12	15	4	15,130
M22×2.5	HJ220R	D	H4	115	38	17	55	16.5	13	16	4	16,170

推奨被削材	構造用鋼 SS400	低炭素鋼 S15C	高炭素鋼 S55C	合金鋼 SCM	調質鋼 HRC25~35	調質鋼 HRC35~40	ステンレス SUS	鋳鉄 FC	タタイル鋳鉄 FCD	アルミニウム合金 AL	銅合金 Cu	チタン合金 Ti
	◎	◎	△	○					△	△	△	