



【HSS】ハンドタップ EA829HA-3A~24BB

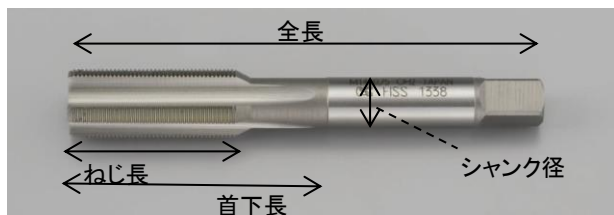

- 材質…ハイス(HSS)
- 被削材…中炭素鋼、ダクタイル鋳鉄、黄銅、黄銅鋳物、青銅、アルミニウム圧延材、アルミニウム合金鋳物、亜鉛合金鋳物、マグネシウム合金鋳物

品番	呼び	食付	全長	ねじ長	首下長	シャンク径	溝数
EA829HA-3A	M3×0.5	9P	46	11	19	4	3
EA829HA-3B	M3×0.5	5P	46	11	19	4	3
EA829HA-3C	M3×0.5	1.5P	46	11	19	4	3
EA829HA-4A	M4×0.7	9P	52	13	21	5	3
EA829HA-4B	M4×0.7	5P	52	13	21	5	3
EA829HA-4C	M4×0.7	1.5P	52	13	21	5	3
EA829HA-5A	M5×0.8	9P	60	16	24	5.5	3
EA829HA-5B	M5×0.8	5P	60	16	24	5.5	3
EA829HA-5C	M5×0.8	1.5P	60	16	24	5.5	3
EA829HA-6A	M6×1	9P	62	19	29	6	3
EA829HA-6B	M6×1	5P	62	19	29	6	3
EA829HA-6C	M6×1	1.5P	62	19	29	6	3
EA829HA-8A	M8×0.5	5P	70	22	37	6.2	4
EA829HA-8B	M8×1.5	5P	70	22	37	6.2	4
EA829HA-8C	M8×1.5	1.5P	70	22	37	6.2	4
EA829HA-8AB	M8×1.25	9P	70	22	37	6.2	4
EA829HA-8BB	M8×1.25	5P	70	22	37	6.2	4
EA829HA-8CB	M8×1.25	1.5P	70	22	37	6.2	4
EA829HA-10A	M10×1	9P	75	24	41	7	4
EA829HA-10B	M10×1	5P	75	24	41	7	4
EA829HA-10C	M10×1	1.5P	75	24	41	7	4
EA829HA-10AB	M10×1.25	9P	75	24	41	7	4
EA829HA-10BB	M10×1.25	5P	75	24	41	7	4
EA829HA-10CB	M10×1.25	1.5P	75	24	41	7	4
EA829HA-10AC	M10×1	9P	75	24	41	7	4
EA829HA-10BC	M10×1	5P	75	24	41	7	4
EA829HA-10CC	M10×1	1.5P	75	24	41	7	4
EA829HA-12A	M12×1.75	9P	82	29	48	8.5	4
EA829HA-12B	M12×1.75	5P	82	29	48	8.5	4
EA829HA-12C	M12×1.75	1.5P	82	29	48	8.5	4
EA829HA-12AB	M12×1.5	9P	82	29	48	8.5	4
EA829HA-12BB	M12×1.5	5P	82	29	48	8.5	4
EA829HA-12CB	M12×1.5	1.5P	82	29	48	8.5	4
EA829HA-12AC	M12×1.25	9P	82	29	48	8.5	4
EA829HA-12BC	M12×1.25	5P	82	29	48	8.5	4
EA829HA-12CC	M12×1.25	1.5P	82	29	48	8.5	4
EA829HA-14A	M14×2	9P	88	30	48	10.5	4
EA829HA-14B	M14×2	5P	88	30	48	10.5	4
EA829HA-14C	M14×2	1.5P	88	30	48	10.5	4
EA829HA-14AB	M14×1.5	9P	88	30	48	10.5	4
EA829HA-14BB	M14×1.5	5P	88	30	48	10.5	4

【HSS】ハンドタップ EA829HA-3A~24BB

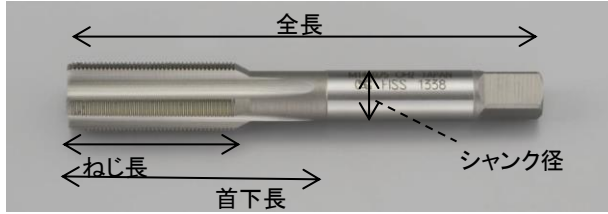

- 材質…ハイス(HSS)
- 被削材…中炭素鋼、ダクタイル鋳鉄、黄銅、黄銅鋳物、青銅、アルミニウム圧延材、アルミニウム合金鋳物、亜鉛合金鋳物、マグネシウム合金鋳物

品番	呼び	食付	全長	ねじ長	首下長	シャンク径	溝数
EA829HA-14CB	M14×1.5	1.5P	88	30	48	10.5	4
EA829HA-14AC	M14×1.25	9P	88	30	48	10.5	4
EA829HA-14BC	M14×1.25	5P	88	30	48	10.5	4
EA829HA-14CC	M14×1.25	1.5P	88	30	48	10.5	4
EA829HA-14AD	M14×1	9P	88	30	48	10.5	4
EA829HA-14BD	M14×1	5P	88	30	48	10.5	4
EA829HA-14CD	M14×1	1.5P	88	30	48	10.5	4
EA829HA-16A	M16×2	9P	95	32	52	12.5	4
EA829HA-16B	M16×2	5P	95	32	52	12.5	4
EA829HA-16C	M16×2	1.5P	95	32	52	12.5	4
EA829HA-16AB	M16×1.5	9P	95	32	52	12.5	4
EA829HA-16BB	M16×1.5	5P	95	32	52	12.5	4
EA829HA-16CB	M16×1.5	1.5P	95	32	52	12.5	4
EA829HA-16AC	M16×1	9P	95	30	50	12.5	4
EA829HA-16BC	M16×1	5P	95	30	50	12.5	4
EA829HA-16CC	M16×1	1.5P	95	30	50	12.5	4
EA829HA-18A	M18×2.5	9P	100	37	55	14	4
EA829HA-18B	M18×2.5	5P	100	37	55	14	4
EA829HA-18C	M18×2.5	1.5P	100	37	55	14	4
EA829HA-18BB	M18×2	5P	100	37	55	14	4
EA829HA-20A	M20×2.5	9P	105	37	58	15	4
EA829HA-20B	M20×2.5	5P	105	37	58	15	4
EA829HA-20C	M20×2.5	1.5P	105	37	58	15	4
EA829HA-20AC	M20×1.5	9P	105	37	58	15	4
EA829HA-20CC	M20×1.5	1.5P	105	37	58	15	4
EA829HA-22A	M22×2.5	9P	115	38	63	17	4
EA829HA-22B	M22×2.5	5P	115	38	63	17	4
EA829HA-22C	M22×2.5	1.5P	115	38	63	17	4
EA829HA-22BB	M22×2	5P	115	38	63	17	4
EA829HA-24A	M24×3	9P	120	45	66	19	4
EA829HA-24B	M24×3	5P	120	45	66	19	4
EA829HA-24C	M24×3	1.5P	120	45	66	19	4
EA829HA-24BB	M24×2	5P	120	45	66	19	4

ミリサイズタップ四角部幅サイズ表

呼び	シャンク径φ	四角部幅	呼び	シャンク径φ	四角部幅	呼び	シャンク径φ	四角部幅
M1~M2	3	2.5	M14~M15	10.5	8	M28	21	17
M3	4	3.2	M16	12.5	10	M30	23	
M4	5	4	M17	13		M32	24	19
M5	5.5	4.5	M18~M19	14	11	M33	25	
M6	6		M20	15	12	M34~M35	26	21
M7~M8	6.2	5	M21	16		13	M36~M38	
M9~M10	7	5.5	M22	17	13	M39~M40	30	23
M11	8	6	M23	18	14	M42	32	26
M12	8.5	6.5	M24~M25	19	15	M45	35	
M13	9.5	7	M26~M27	20				

サイズ(mm)