


SGSP

SGスパイラルタップ

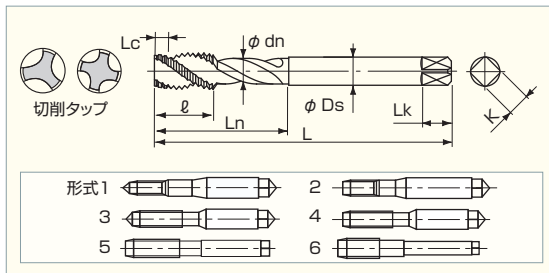

・単位(Unit):mm/

記号 Code No.	呼び Thread Size	等級 TAP Limit		食付(P) Lc (P)	全長 L	ねじ長 ϕ	溝数 Flutes	シャンク径 Ds	首下長さ Ln	首径 dn	形式 Type
9M1.25R	M9 × 1.25	REG	P3	2.5	72	8.8	3	7.0	29.8	7.6	6
9M1R	M9 × 1	REG	P3	2.5	72	8.8	3	7.0	29.8	7.9	6
9M0.75R	M9 × 0.75	REG	P3	2.5	72	8.8	3	7.0	29.8	8.1	6
10M1.5R	M10 × 1.5	REG	P3	2.5	75	10.5	3	7.0	31.4	8.3	6
10M1.5R+1		REG+1	P4								
10M1.5R+2		REG+2	P5								
10M1.25R	M10 × 1.25	REG	P3	2.5	75	10.5	3	7.0	31.4	8.7	6
10M1.25R+1		REG+1	P4								
10M1R	M10 × 1	REG	P3	2.5	75	10.5	3	7.0	31.4	8.9	6
10M1R+1		REG+1	P4								
10M0.75R	M10 × 0.75	REG	P3	2.5	75	10.5	3	7.0	31.4	9.1	6
10M0.75R+1		REG+1	P4								

EA829NA-10C

EA829NA-10B