


# ダイヤモンドコアビット EA870B-28~-160

VER.1.1

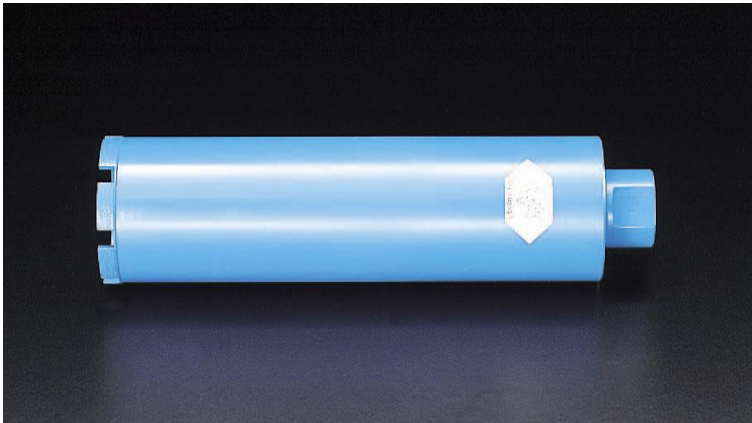

- ダイヤモンドリル  
EA870A-1、-3専用
- 取り付けネジ…M27

品番	サイズ	ビット				シャンク				通常セグメント				重量 kg
	mm	外径	内径	全長	有効長	外径	内径	先端	厚さ	H	L	W	数	
EA870B-28	φ28	28.0	22.0	305.0	245.0	26.0	23.0	27.0	1.5	7.0	15.5	3.00	4	0.53
EA870B-32	φ32	32.0	25.6	311.0	251.0	30.0	27.0	31.0	1.5	7.0	25.0	3.20	3	0.55
EA870B-40	φ40	39.6	33.6	299.0	256.0	38.0	35.0	39.0	1.5	7.0	25.0	3.00	4	0.62
EA870B-52	φ52	51.6	45.6	294.0	250.0	50.0	47.0	51.0	1.5	8.0	25.0	3.00	5	0.77
EA870B-65	φ65	65.0	58.6	294.0	250.0	63.0	60.0	64.0	1.5	8.0	20.0	3.20	7	0.97
EA870B-70	φ70	70.0	63.6	294.0	250.0	68.0	65.0	69.0	1.5	8.0	20.0	3.20	8	1.05
EA870B-75	φ75	75.1	68.6	293.5	250.0	73.0	70.0	74.0	1.5	7.5	25.0	3.25	7	1.13
EA870B-80	φ80	80.1	73.6	293.5	250.0	78.0	75.0	79.0	1.5	7.5	25.0	3.25	7	1.21
EA870B-90	φ90	90.1	83.6	293.5	250.0	88.0	85.0	89.0	1.5	7.5	25.0	3.25	8	1.38
EA870B-100	φ100	100.1	93.6	293.5	250.0	98.0	95.0	99.0	1.5	7.5	25.0	3.25	6	1.57
EA870B-110	φ110	110.1	103.6	293.5	250.0	108.0	105.0	109.0	1.5	7.5	25.0	3.25	8	1.76
EA870B-120	φ120	120.1	113.6	293.5	250.0	118.0	115.0	119.0	1.5	7.5	25.0	3.25	8	1.97
EA870B-130	φ130	130.1	123.6	293.5	250.0	128.0	125.0	129.0	1.5	7.5	25.0	3.25	10	2.18
<del>廃番</del> EA870B-150	<del>φ150</del>	<del>150.1</del>	<del>143.6</del>	<del>293.5</del>	<del>250.0</del>	<del>148.0</del>	<del>145.0</del>	<del>149.0</del>	<del>1.5</del>	<del>7.5</del>	<del>25.0</del>	<del>3.25</del>	<del>10</del>	<del>2.64</del>
<del>廃番</del> EA870B-160	<del>φ160</del>	<del>160.1</del>	<del>153.6</del>	<del>293.5</del>	<del>250.0</del>	<del>158.0</del>	<del>155.0</del>	<del>159.0</del>	<del>1.5</del>	<del>7.5</del>	<del>25.0</del>	<del>3.25</del>	<del>12</del>	<del>2.89</del>

廃番  
廃番

