


EA911AG-5~-7、-25~-27、-45~-47、-65~-67

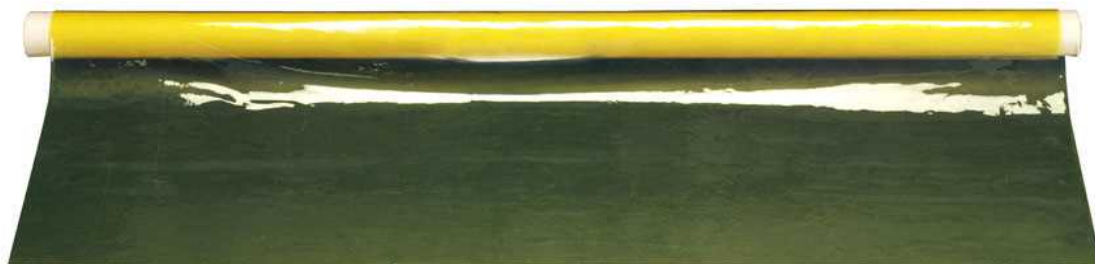

品番	厚さ	長さ	重量	硬度	引張切断強さ kgf		伸び率 %		直角形引裂強さ kgf		耐寒温度 ℃	
					縦	横	縦	横	縦	横		
EA911AG-5	0.3mm	2m	0.9kg	#400	7.2	6.4	270	280	2.37	2.33	-25	廃番
EA911AG-6	0.3mm	5m	2.25kg	#400	7.2	6.4	270	280	2.37	2.33	25	廃番
EA911AG-7	0.3mm	10m	4.5kg	#400	7.2	6.4	270	280	2.37	2.33	-25	
EA911AG-25	0.5mm	2m	1.32kg	#400	12.3	11	290	290	2.79	2.73	-40	廃番
EA911AG-26	0.5mm	5m	3.3kg	#400	12.3	11	290	290	2.79	2.73	40	廃番
EA911AG-27	0.5mm	10m	6.6kg	#400	12.3	11	290	290	2.79	2.73	-40	
EA911AG-45	0.8mm	2m	2.08kg	#480	22.6	21.7	340	400	6.87	7.2	40	廃番
EA911AG-46	0.8mm	5m	5.2kg	#480	22.6	21.7	340	400	6.87	7.2	40	廃番
EA911AG-47	0.8mm	10m	10.4kg	#480	22.6	21.7	340	400	6.87	7.2	40	廃番
EA911AG-65	1.0mm	2m	2.56kg	#480	26.5	25.8	370	430	8.04	8.27	-45	廃番
EA911AG-66	1.0mm	5m	6.4kg	#480	26.5	25.8	370	430	8.04	8.27	-45	廃番
EA911AG-67	1.0mm	10m	12.8kg	#480	26.5	25.8	370	430	8.04	8.27	-45	

- 材質…PVC
- 色…黄色
- 幅…915mm

○値は実測値です。保証値ではありません。