


# EA940BN-1, -2仕様

## 防水型プラグ

セフティワッシャ付

単位 : mm

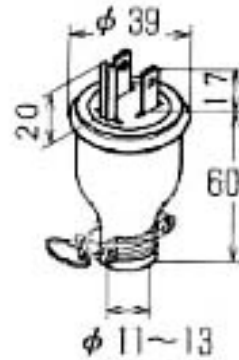

**EA940BN-1**  
15A 125V  
接地防水プラグ  
15A. 125V.



**EA940BN-2**  
15A 125V  
接地防水コネクターポデー  
15A. 125V

### 適用電線(mm<sup>2</sup>)

	2CT. 2RNCT	2PNCT	VCT. VCT(S)	適用圧着端子
EA940BN-1	1.25 ~ 2	2	2	0.75 ~ 1.25mm <sup>2</sup> . . . R1.25 - 3.5
EA940BN-2				2mm <sup>2</sup> . . . R2 - 3.5