


EA940CL-15
(埋め込みコンセント)

- 定格容量 20A/250V
- 適用電線 $2\text{mm}^2 \sim 3.5\text{mm}^2$

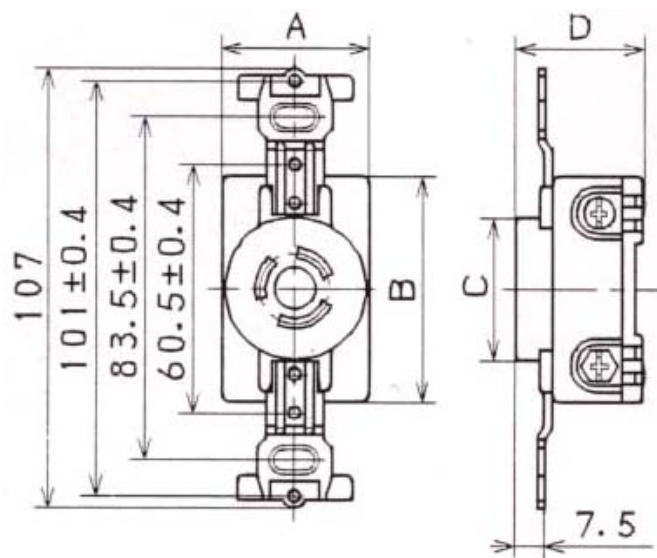

A: 37mm C: $\phi 34.5\text{mm}$
B: 56mm D: 32mm

