



Gタイプ

●Gタイプのハブ付ですから、接続も解除も一発でOKです。

〈1ヶ用〉



1方出

〈2ヶ用〉



1方出



2方出(S)



2方出(S)




1方出
(下面2個口)



1方出
(下面2個口)


〈1ヶ用〉

■1方出

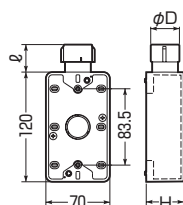


〈2ヶ用〉


■1方出

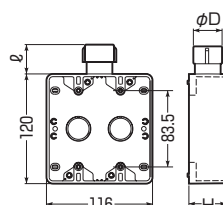


■2方出(S)

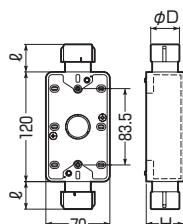


■2方出(S)

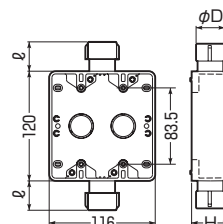

■1方出(下面2個口)

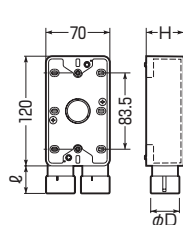

■1方出(下面2個口)

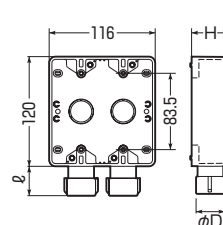

種 類	ページ	品 番	ミルキーホワイト	グレー	適合管	φD	ℓ	H	入数	最小入数	
1ヶ用	1方出	SW1-16FG	SW1-16FGM	SW1-16FGH	※PF管16	31.4	30	41	20	1	EA940CP-22
		SW1-22FGS	SW1-22FGSM	SW1-22FGSH	※PF管22	39.3	34	41	20	1	
		SW1-22FG	SW1-22FGM	SW1-22FGH	※PF管22	39.3	34	49	20	1	EA940CP-24
		SW1-28FG	SW1-28FGM	SW1-28FGH	※PF管28	46.9	38	49	20	1	EA940CP-25
	2方出(S)	SW2S-16FG		SW2S-16FGH	※PF管16	31.4	30	41	20	1	
		SW2S-22FGS		SW2S-22FGSH	※PF管22	39.3	34	41	20	1	
		SW2S-22FG		SW2S-22FGH	※PF管22	39.3	34	49	20	1	
		SW2S-28FG		SW2S-28FGH	※PF管28	46.9	38	49	20	1	
	1方出 (下面2個口)	SW2-16FG	SW2-16FGM	SW2-16FGH	※PF管16	31.4	30	41	20	1	
2ヶ用	1方出	SW1-16WFG		SW1-16WFGH	※PF管16	31.4	30	47.5	10	1	
		SW1-22WFG		SW1-22WFGH	※PF管22	39.3	34	47.5	10	1	
		SW1-28WFG		SW1-28WFGH	※PF管28	46.9	38	47.5	10	1	
	2方出(S)	SW2S-16WFG		SW2S-16WFGH	※PF管16	31.4	30	47.5	10	1	
		SW2S-22WFG		SW2S-22WFGH	※PF管22	39.3	34	47.5	10	1	
		SW2S-28WFG		SW2S-28WFGH	※PF管28	46.9	38	47.5	10	1	
	1方出 (下面2個口)	SW2-16WFG		SW2-16WFGH	※PF管16	31.4	30	47.5	10	1	
		SW2-22WFG		SW2-22WFGH	※PF管22	39.3	34	47.5	10	1	

※MF、MFXは除く