


SLQ-4N-46

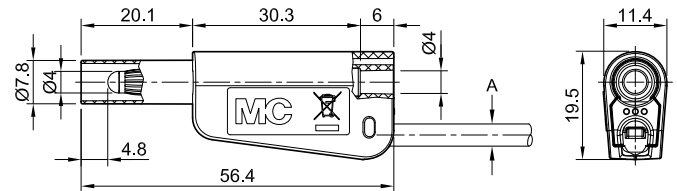

Item number 66.2022-*

Stackable, Ø 4 mm, with spring-loaded MULTILAM, for self-assembly of test leads. With rigid insulating sleeve. Nickel-plated version. Cross hole for solder connection.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT II, 32 A / 600 V, CAT III, 32 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	20 21 22 23 24 25 26 27 28 29 30
Outer diameter	4.6 mm
Test accessory acc. to	IEC EN 61010-031
Component parts	KT-SL-4-46
Approvals	UR