

EA940MX-1~MX-75 インバーター(3相モーター用)


品番	出力				電源					保護構造 (JEM1030)	冷却方式	概略重量 (kg)	
	モータ容量 (KW)	定格容量 (KVA)	定格電流 (A)	過負荷電流定格	電圧	定格入力	交流電圧・ 周波数	交流電圧 許容変動	周波数許容 変動				電源設備容量 (KVA)
EA940MX-1	0.1	0.3	0.8	150%60s、 200%0.5s (反限時特性)	3相 200 ~ 240V	3相200~ 240V50Hz/60Hz	170~ 264V50H z/60Hz	±5%		0.4	閉鎖型(IP20)	自冷	0.5
EA940MX-2	0.2	0.6	1.4							0.7			1.0
EA940MX-4	0.4	1.0	2.5							1.2			1.8
EA940MX-7.5	0.75	1.7	4.2							2.1		3.0	
EA940MX-15	1.5	2.8	7.0							4.0		5.5	
EA940MX-22	2.2	4.0	10.0							5.5		7.5	
EA940MX-37	3.7	6.6	16.5							9.0		12.0	
EA940MX-55	5.5	9.5	23.8							12.0		16.5	
EA940MX-75	7.5	12.7	31.8							17.0		23.0	




MX-1~7.5

品番	D	D1
MX-1	80.5	10
MX-2		
MX-4	112.5	42
MX-7.5	132.5	62

MX-15~-37

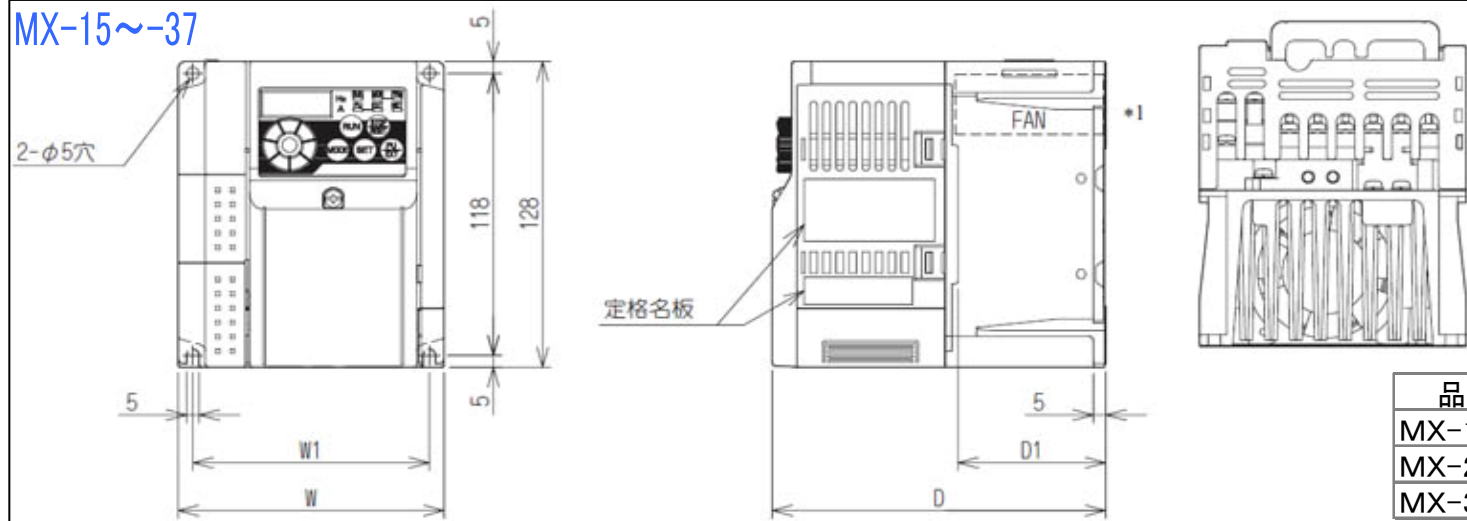

品番	W	W1	D	D2
MX-15	108	96	135.5	60
MX-22				
MX-37	170	158	142.5	66.5

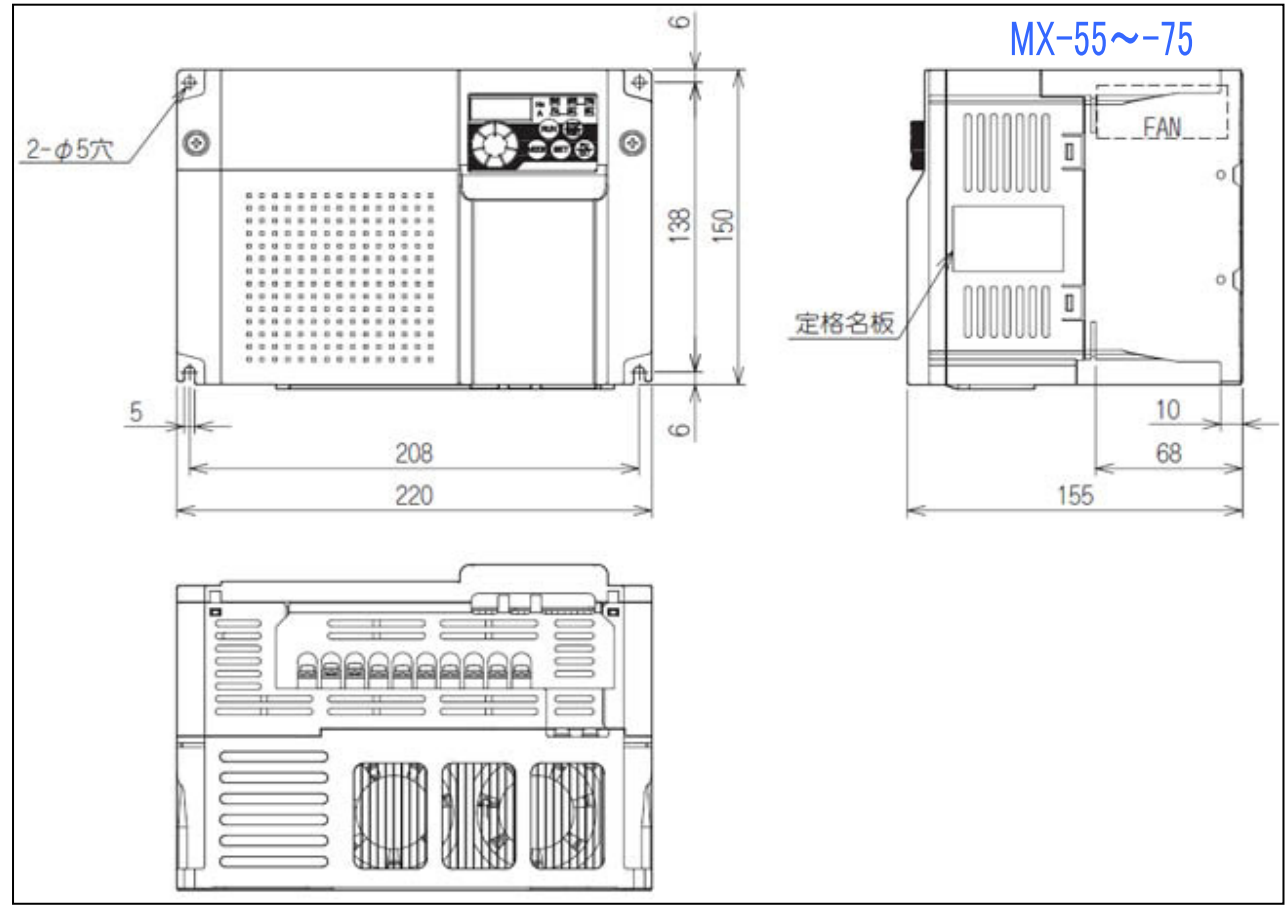

MX-55~-75