


## [塩化ビニール製]ボルト


### ・全ねじ

EA945AY-81、-82、-101～-104、  
-121～-123、-161

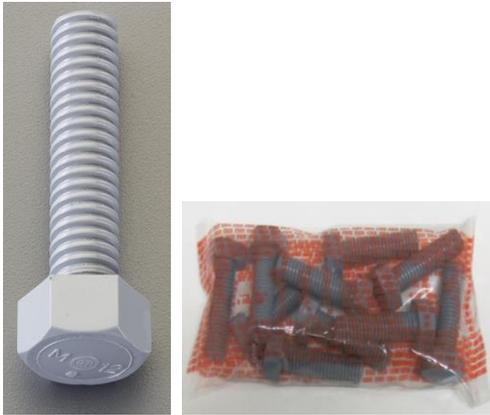

### ・半ねじ

EA945AY-83～-86、-105～-107  
-124～-126、-162～-166

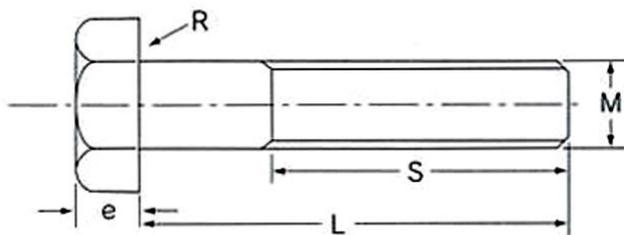

- 材質 … 硬質塩化ビニール(U-PVC)
- 入数 … 10本
- 特長 … 硬質塩化ビニール一体成形品です。耐食性に優れています。

品番	ねじ				サイズ(mm)		重量 (10本)	仕様
	M(呼び)	L(mm)	S(mm)	ピッチ	e	R		
EA945AY-81	M8	20	18	1.25	5.5	0.2	20g	全ねじ
EA945AY-82		25	23				20g	全ねじ
EA945AY-83		32	22				30g	半ねじ
EA945AY-84		38	22				30g	半ねじ
EA945AY-85		50	22				40g	半ねじ
EA945AY-86		55	22				40g	半ねじ
EA945AY-101	M10	14	12	1.5	7.0	0.2	30g	全ねじ
EA945AY-102		20	18				40g	全ねじ
EA945AY-103		25	23				40g	全ねじ
EA945AY-104		30	28				50g	全ねじ
EA945AY-105		40	26				60g	半ねじ
EA945AY-106		50	26				60g	半ねじ
EA945AY-107	60	26	70g	半ねじ				
EA945AY-121	M12	25	23	1.75	8.0	0.3	60g	全ねじ
EA945AY-122		30	28				70g	全ねじ
EA945AY-123		40	38				80g	全ねじ
EA945AY-124		50	30				90g	半ねじ
EA945AY-125		60	30				110g	半ねじ
EA945AY-126		70	30				120g	半ねじ
EA945AY-161	M16	40	38	2.0	10.0	0.4	150g	全ねじ
EA945AY-162		50	38				170g	半ねじ
EA945AY-163		60	38				200g	半ねじ
EA945AY-164		70	38				220g	半ねじ
EA945AY-165		80	38				240g	半ねじ
EA945AY-166		95	38				280g	半ねじ