




Pipe Hangers & Supports

アカギのバンド アカギ式 配管支持金具

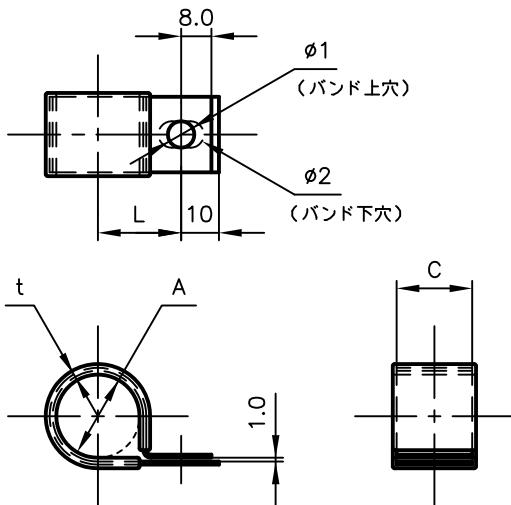

御承認願図
WEB図面

サイズ	A	C	L	t	φ1	φ2
SD-6	ø6.5	15	13	0.6	ø6.5	ø6.5×8.5
SD-8	ø8.0	20	15	"	ø7.0	ø7.0×12
SD-10	ø10	"	16	"	"	"
SD-12	ø12	"	17	"	"	"
SD-15	ø15	"	18	0.8	"	"
SD-18	ø18	20	20	0.8	ø7.0	ø7.0×12
SD-20	ø20	"	21	"	"	"
SD-22	ø22	"	22	"	"	"
SD-25	ø25	"	23	"	"	"
SD-28	ø28	"	25	"	"	"
SD-30	ø30	20	26	0.8	ø7.0	ø7.0×12
SD-35	ø35	"	28	"	"	"
SD-40	ø40	"	31	"	"	"
SD-45	ø45	"	34	"	"	"
SD-50	ø50	"	36	"	"	"
SD-55	ø55	20	39	0.8	ø7.0	ø7.0×12
SD-60	ø60	"	42	"	"	"

No,1		No,2		No,3	
No,4		No,5		No,6	
品番 (No. OF PART) A10450	図面番号 (DRAWING No.) SAWA-4105	3RD ANGLE PROJECTION			
品名 (NAME OF PART) クリップサドル (SDタイプ)	サイズ SD-6~SD-60	尺度 (SCALE) 1:2(図はSD-22)			
材料 (MATERIAL) SPCC、軟質塩化ビニール	製図 (DWG)	検図 (CHECKED)	承認図 (MGR)	作成年月日 (PRERAED) 平成17年4月15日	
表面処理 (FACE OF COAT) 塗装色=ブラック				配管支持金具の アカギ 株式会社 アカギ	