


単位 mm

厚鋼電線管ねじ

JIS B0204

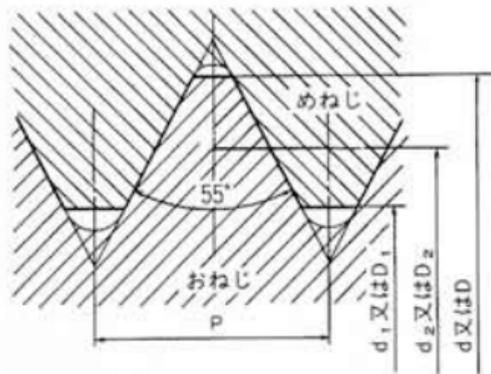

ねじの呼び	適用する管の呼び	ねじ山数 (25.4mm) につき n	ピッチ P (参考)	ひっかきの高さ H_1	おねじ			制御盤 取付穴 最小寸法
					外径 d	有効径 d_2	谷の径 d_1	
					めねじ			
					谷の径 D	有効径 D_2	内径 D_1	
CTG 16	16	14	1.8143	1.017	20.955	19.793	18.922	22
CTG 22	22	14	1.8143	1.017	26.441	25.279	24.408	27
CTG 28	28	11	2.3091	1.294	33.249	31.770	30.661	34
CTG 36	36	11	2.3091	1.294	41.910	40.431	39.322	43
CTG 42	42	11	2.3091	1.294	47.803	46.324	45.215	49
CTG 54	54	11	2.3091	1.294	59.614	58.135	57.026	61
CTG 70	70	11	2.3091	1.294	75.184	73.705	72.596	76
CTG 82	82	11	2.3091	1.294	87.884	86.405	85.296	89
CTG 92	92	11	2.3091	1.294	100.330	98.851	97.742	102
CTG104	104	11	2.3091	1.294	113.030	111.551	110.442	115