


単位 mm

薄鋼電線管ねじ

JIS B0204

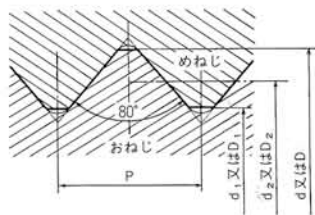

ねじの呼び	適用する管の呼び	ねじ山数 (25.4mmにつき) n	ピッチ P (参考)	ひっかきの高さ H ₁	おねじ			制御盤 取付穴 最小寸法
					外径 d	有効径 d ₂	谷の径 d ₁	
					めねじ			
					谷の径 D	有効径 D ₂	内径 D ₁	
CTC19	19	16	1.5875	0.696	19.100	18.343	17.708	20
CTC25	25	16	1.5875	0.696	25.400	24.643	24.008	26
CTC31	31	16	1.5875	0.696	31.800	31.043	30.408	33
CTC39	39	16	1.5875	0.696	38.100	37.343	36.708	39
CTC51	51	16	1.5875	0.696	50.800	50.043	49.408	52
CTC63	63	16	1.5875	0.696	63.500	62.743	62.108	65
CTC75	75	16	1.5875	0.696	76.200	75.443	74.808	77