

KN,KS

ナールド ノブ

標準
在庫品

RHS

SUS

材質の特性
P.2231

追加加工

ネジ
カット

ネジ
締付け

P.2200~

Original ELESA Model B.193

elasa



(スチール製)



(SUS製)




KS
(オネジ)




KN
(メネジ)




KN-T
(メネジ貫通)

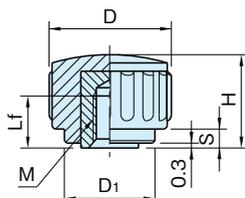

KN KN-SUS
(メネジ)

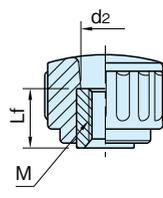

KN-T
(メネジ貫通)

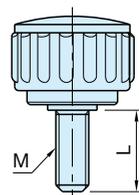

KS KS-SUS
(オネジ)

タイプ	ノブ	メネジ	オネジ
KN	フェノール樹脂 光沢仕上げ ブラック	黄銅 (カドミウム低減材)	—
KN-T		SUS303	—
KN-SUS			—
KS		—	S10C 亜鉛メッキ
KS-SUS		—	SUS303

KN KN-SUS (メネジ)

黄銅製		SUS製		D	M	H	D ₁	S	質量 (g)
品番	Lf	品番	Lf						
KN15C	6	—	—	15	M 3×0.5	11	11	2	4
KN15		—	—		M 4×0.7				
KN15B	5	KN15B-SUS	6	18	M 5×0.8	12	13	3	5
KN18		—	—		—				
KN20	6	KN20 -SUS	6	22	M 6×1	14	15	4	8
KN25	10	KN25 -SUS	10	26					
KN30		KN30 -SUS		31	M 8×1.25	23	27	8	30
KN35		—		—					
KN40	13	—	—	40	M10×1.5	32	36	12	73
KN50A	17	—	—	50					
KN50B	20	—	—		—	—	—	—	—

KN-T (メネジ貫通)

	品番	D	M	H	D ₁	S	L _f	d ₂	質量 (g)
	KN15T	15	M 4×0.7	11	11	2	10	6	4
	KN18T	18	M 5×0.8	12	13	3		7	5
EA948AE-23	KN20T	22	M 6×1	14	15	4	11	8	8
EA948AE-24	KN25T	26		M 8×1.25	18	19	6	15	10
EA948AE-25	KN25TA		17						
EA948AE-26	KN30T	31	M 8×1.25	18	24	6	15	13	21
EA948AE-27	KN30TA								24
EA948AE-28	KN40T	40	M10×1.5	26	29	10		14	40

KS [KS-SUS] (オネジ)

スチール製	SUS製	D	M	H	D ₁	S	L	質量 (g)	
品番	品番								
KS15×6C	KS15×6C-SUS	15	M 3×0.5	11	11	2	6	3	
KS15×10C	KS15×10C-SUS						10	4	
KS15×6A	KS15×6A-SUS						6	3	
KS15×10A	KS15×10A-SUS		10				4		
KS15×16A	KS15×16A-SUS		16				5		
KS15×10B	KS15×10B-SUS		10						
KS15×16B	KS15×16B-SUS	16	6						
KS18×10	—	18	M 5×0.8	12	13	3	10	7	
KS18×16	—						16		
KS20×10	KS20×10 -SUS	22	M 6×1	14	15	4	10	9	
KS20×16	KS20×16 -SUS						16	10	
KS20×25	—						25	12	
KS25×16	KS25×16 -SUS	26	M 6×1	18	19	6	16	14	
KS25×25	KS25×25 -SUS						25	16	
KS25×16A	—						16	20	
KS25×25A	—						25	23	
KS30×16	—	31	M 8×1.25	18	24	6	16	25	
KS30×25	—						25	28	
KS30×40	—						40	32	
KS35×25	—	36	M 8×1.25	23	27	8	25	38	
KS35×40	—						40	42	
KS40×30	—	40	M10×1.5	26	29	10	30	59	
KS50×40	—	50		32	36	12	40	94	

技術データ

使用温度 max.110℃ min.-20℃

追加工を承ります!
