


EA948BC-41 ~ -43
 [ステンレス製]雌ねじノブ



材 質 … SUS304
 バレル研磨仕上げ

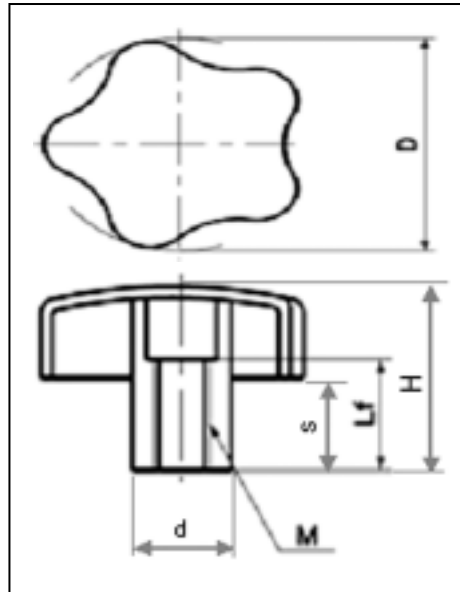

品番	ねじサイズ M × Lf	サイズ(mm)				重量 (g)
		D	H	s	d	
EA948BC-41	M8 × 15	40	24	12.0	14	37
EA948BC-42	M10 × 18	50	31	17.5	18	65
EA948BC-43	M12 × 22	60	39	21.0	20	107