


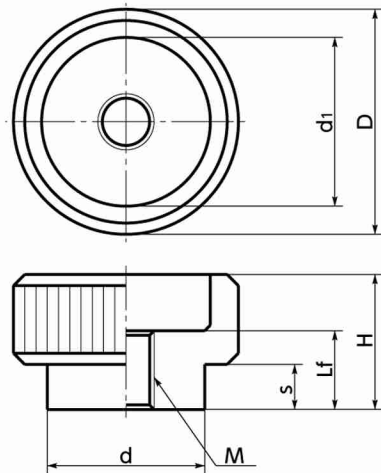

- スティール製・ステンレス製を標準化。
- 材質・仕上げ

 RoHS指令適合

	KCF-BK スティール製	KCFS ステンレス製
本体	S45C 四三酸化鉄皮膜(黒)	SUS303

単位: mm

品番 スティール製	EA品番	品番 ステンレス製	EA品番	D	M(並目)	Lf	H	s	d	d1	質量(g)
KCF-20-M5-BK	EA948BD-1	KCFS-20-M5	EA948BD-11	20	M5	7	12	4	14	15	17
KCF-24-M6-BK	EA948BD-2	KCFS-24-M6	—	24	M6	8	14	4	16	18	30
KCF-30-M8-BK	EA948BD-3	KCFS-30-M8	EA948BD-13	30	M8	10	17	5	20	24	50
KCF-36-M10-BK	EA948BD-4	KCFS-36-M10	EA948BD-14	36	M10	12	20	6	28	30	90
KCF-40-M12-BK	EA948BD-5	KCFS-40-M12	EA948BD-15	40	M12	16	24	8	32	34	125