
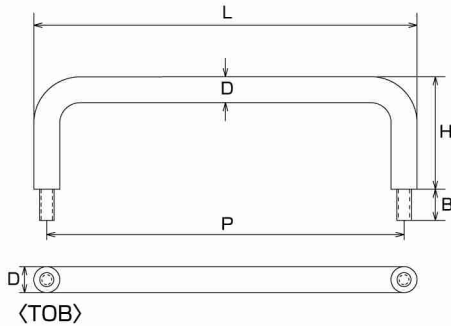


# 引き取手 Drawer Handle

〈めねじ〉材質：ステンレス SUS304

(mm)

品番	D	L	P	H	B	捻径	weight (g)	参考使用荷重		E A品番	コード No.
								(kgf)	(kN)		
TOA-6-40	6	46	40	23	7	M-4	14	20	0.20	EA948BJ-21	1775
TOA-6-60	6	66	60	23	7	M-4	18	20	0.20	EA948BJ-22	1776
TOA-6-80	6	86	80	30	7	M-4	26	20	0.20	EA948BJ-23	1777
TOA-7-68	7	75	68	30	8	M-5	30	45	0.44	EA948BJ-24	1992
TOA-8-90	8	98	90	30	8	M-5	48	45	0.44	EA948BJ-25	1778
TOA-8-100	8	108	100	40	8	M-5	61	45	0.44	EA948BJ-26	1779
TOA-8-110	8	118	110	40	8	M-5	63	45	0.44	EA948BJ-27	1780
TOA-8-120	8	128	120	40	8	M-5	67	45	0.44	EA948BJ-28	1781
TOA-10-100	10	110	100	50	8	M-6	105	60	0.59	EA948BJ-29	1782
TOA-10-110	10	120	110	50	8	M-6	112	60	0.59	EA948BJ-30	1783
TOA-10-120	10	130	120	50	8	M-6	118	60	0.59	EA948BJ-31	1784
TOA-12-150	12	162	150	50	12.5	M-8	181	75	0.74	EA948BJ-32	1785
TOA-12-200	12	212	200	50	12.5	M-8	226	75	0.74	EA948BJ-33	1786
TOA-12-250	12	262	250	50	12.5	M-8	269	75	0.74	EA948BJ-34	1787

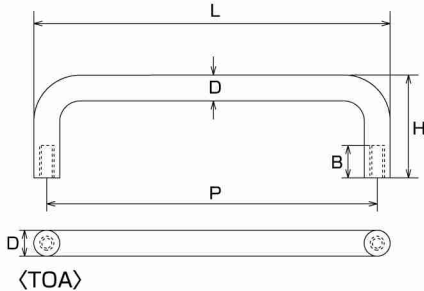

〈おねじ〉材質：ステンレス SUS304

(mm)

品番	D	L	P	H	B	捻径	weight (g)	参考使用荷重		E A品番	コード No.
								(kgf)	(kN)		
TOB-4-20	4	24	20	22	7	M-2.6	6	10	0.10	EA948BJ-40	2345
TOB-6-40	6	46	40	23	7	M-4	19	20	0.20	EA948BJ-41	1785
TOB-6-60	6	66	60	23	7	M-4	23	20	0.20	EA948BJ-42	1786
TOB-6-80	6	86	80	30	7	M-4	30	20	0.20	EA948BJ-43	1787
TOB-7-68	7	75	68	30	11	M-5	39	45	0.44	EA948BJ-44	1994
TOB-8-90	8	98	90	30	11	M-5	57	45	0.44	EA948BJ-45	1788
TOB-8-100	8	108	100	40	11	M-5	68	45	0.44	EA948BJ-46	1789
TOB-8-110	8	118	110	40	11	M-5	72	45	0.44	EA948BJ-47	1790
TOB-8-120	8	128	120	40	11	M-5	76	45	0.44	EA948BJ-48	1791
TOB-9-100	9	109	100	30	11	M-5	75	45	0.44	EA948BJ-45B	1995
TOB-10-100	10	110	100	50	11	M-6	119	60	0.59	EA948BJ-49	1792
TOB-10-110S	10	120	110	40	11	M-6	111	60	0.59	EA948BJ-49B	2346
TOB-10-110	10	120	110	50	11	M-6	124	60	0.59	EA948BJ-50	1793
TOB-10-120S	10	130	120	40	11	M-6	116	60	0.59	EA948BJ-50B	2347
TOB-10-120	10	130	120	50	11	M-6	132	60	0.59	EA948BJ-51	1794
TOB-12-150	12	162	150	50	20	M-8	218	75	0.74	EA948BJ-52	1795
TOB-12-188	12	200	188	50	20	M-8	252	75	0.74	EA948BJ-52B	1796
TOB-12-200	12	212	200	50	20	M-8	262	75	0.74	EA948BJ-53	1797
TOB-12-238	12	250	238	50	20	M-8	293	75	0.74	EA948BJ-53B	1798
TOB-12-250	12	262	250	50	20	M-8	305	75	0.74	EA948BJ-54	1799
TOB-12-288	12	300	288	50	20	M-8	337	75	0.74	EA948BJ-54B	1800

※おねじ (TOB) には、六角ナット・スプリングワッシャー  
各2個付です。

〈鏡面仕上げ〉

