

FLR,FLS

フィックスド レバー

標準 在庫品 R&S





FLR
(丸穴)




FLS
(角穴)

本体
亜鉛ダイカスト (ZDC1)
塗装 シルバーグレー

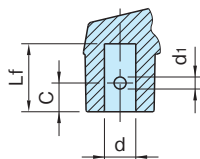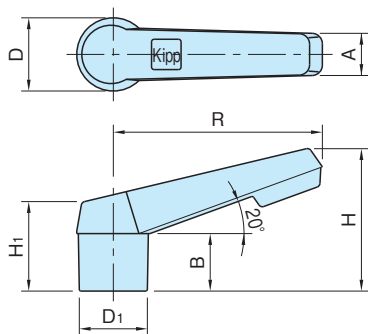

FLR
(丸穴)

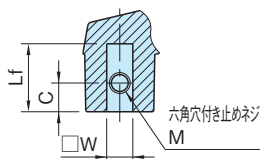

FLS
(角穴)

FLR (丸穴)

品番	R	d (H9)	H	D	H ₁	D ₁	A	B	Lf	d ₁	C	質量 (g)
EA948CJ-1 FLR 6	40	6	27	14	17	13.5	8	11	13	2.3	5.5	25
EA948CJ-2 FLR 8	65	8	36.5	18.5	18	18	9	11	16	2.8	7	50
EA948CJ-3 FLR10	80	10	45	22	22	21.5	11	14	18	3.8	8.5	80
EA948CJ-4 FLR12	95	12	54	26	26	25.5	13	17	20			135

FLS (角穴)

品番	R	W (H11)	H	D	H ₁	D ₁	A	B	Lf	M	C	質量 (g)
FLS 5	40	5	27	14	17	13.5	8	11	13	M4×0.7	5.5	25
FLS 6	65	6	36.5	18.5	18	18	9	11	16	M4×0.7	7	50
FLS 8	80	8	45	22	22	21.5	11	14	18	M4×0.7	8.5	80
FLS10	95	10	54	26	26	25.5	13	17	20	M5×0.8	10.5	135
FLS12	110	12	63	31	31	30.5	16	21	26			225

付属品

FLS: 六角穴付き止めネジ

特長

- ・ **FLR** 丸穴はピンホール付きです。
- ・ **FLS** 角穴は六角穴付き止めネジにて取付け可能です。