
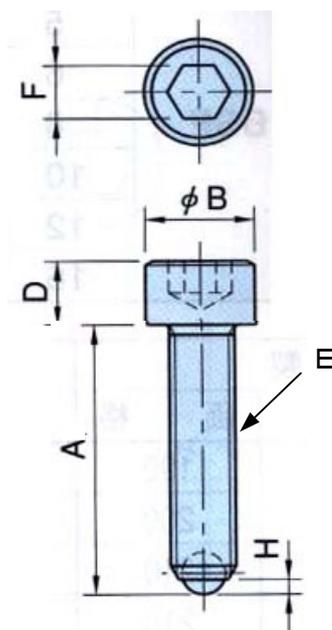
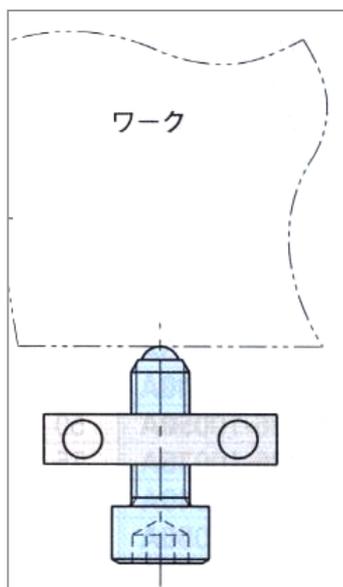


**EA948DJ-301~323**  
(ボールキャップスクリュー)

- 全球タイプは点で受けます。
- 本体材質 SCM435  
処理 黒染め  
硬度 HRC33~39
- ボール材質 SUJ2  
硬度 HRC56~60

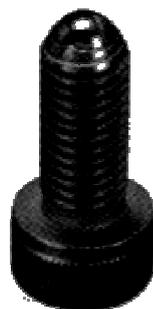

	ボール径	A	B	D	E	F	H	重量(g)
DJ-301		16.9						5.3
DJ-302	φ4.0	25.9	10	6	M6X1	5	1.4	7.3
DJ-303		40.9						11
DJ-306		21.3						13.5
DJ-307	φ5.5	36.3	13	8	M8X1.25	6	1.9	19
DJ-308		51.3						25
DJ-311		26.7						26
DJ-312	φ7.0	41.7	16	10	M10X1.5	8	2.4	34
DJ-313		61.7						47
DJ-316		32						40
DJ-317	φ8.7	52	18	12	M12X1.75	10	2.85	56
DJ-318		82						83
DJ-321		43						91
DJ-322	φ12.0	63	24	16	M16X2	14	4	122
DJ-323		93						173

(単位mm)