


EA948E-21~EA948E-42 [焼入]クランプボルト

RoHS指令適合品

●材質

本体:SCM435、焼入焼戻、黒染め、HRC33~39

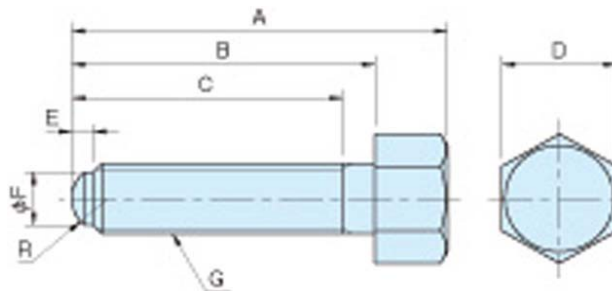

品番	サイズ(mm)								クランプ力(N)	締付トルク(N・m)	重量(g)
	A	B	C	D	E	F	G	R			
EA948E-21	38	30	27	10	2.5	4.5	M6X1	R5	34.000	41	9
EA948E-22	48	40	37								10
EA948E-23	58	50	47								12
EA948E-24	50	40	37	13	3	5.5	M8X1.25	R6	53.000	84	21
EA948E-25	60	50	47								24
EA948E-26	70	60	57								26
EA948E-27	52	40	37	17	3.5	7.5	M10X1.5	R8	89.000	178	38
EA948E-28	62	50	47								42
EA948E-29	72	60	57								46
EA948E-30	75	60	55	19	5	9	M12X1.75	R9	100.000	240	70
EA948E-31	95	80	75								80
EA948E-32	115	100	95								95
EA948E-33	140	125	120	24	6	12	M16X2	R12	130.000	417	115
EA948E-34	100	80	75								165
EA948E-35	120	100	95								185
EA948E-36	145	125	120	30	7	15	M20X2.5	R15	177.000	706	215
EA948E-37	105	80	70								285
EA948E-38	125	100	90								320
EA948E-39	150	125	115	36	8	19.5	M24X3	R20	219.000	1.050	365
EA948E-40	125	100	90								460
EA948E-41	150	125	115								525
EA948E-42	175	150	140	590							

廃番
廃番
廃番
廃番
廃番
廃番
廃番
廃番
廃番
廃番
廃番
廃番