


図面／規格
【（＋）丸木ねじ】

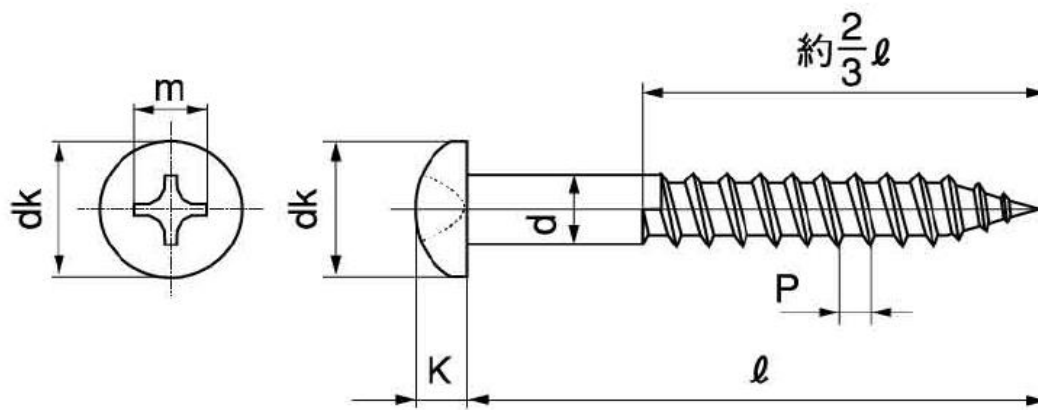

EA949EDシリーズ

	呼び径	十字穴 の番号	d		dk		K		m
			基準 寸法	許容差	基準 寸法	許容差	基準 寸法	許容差	
-101、-102	2.1	1	2.1	± 0.07	3.9	± 0.2	1.6	± 0.1	2.5
-103～-105	2.4		2.4		4.4		1.8		2.7
-106～-109	2.7		2.7		5.0		2.0		2.9
-110～-114	3.1	2	3.1	± 0.1	5.7	± 0.25	2.3	± 0.15	3.7
-115～-118	3.5		3.5		6.5		2.5		3.9
-119～-124	3.8		3.8		7.0		2.7		4.1
-125～-130	4.1		4.1		7.6	± 0.3	2.9		4.3
-131～-135	4.5		4.5		8.3		3.1		4.5
-136～-141	4.8	3	4.8	± 0.12	8.9		3.3	± 0.2	4.7
	5.1		5.1		9.4	± 0.35	3.5		5.9
	5.5		5.5		10.2		3.8		6.1
	5.8		5.8		10.7	± 0.4	4.0		6.3
-142～-146	6.2	4	6.2	± 0.15	11.5		4.2		6.6
	8.0		8.0		14.8		5.3		8.7