


図面／規格 【ピアSPAN】

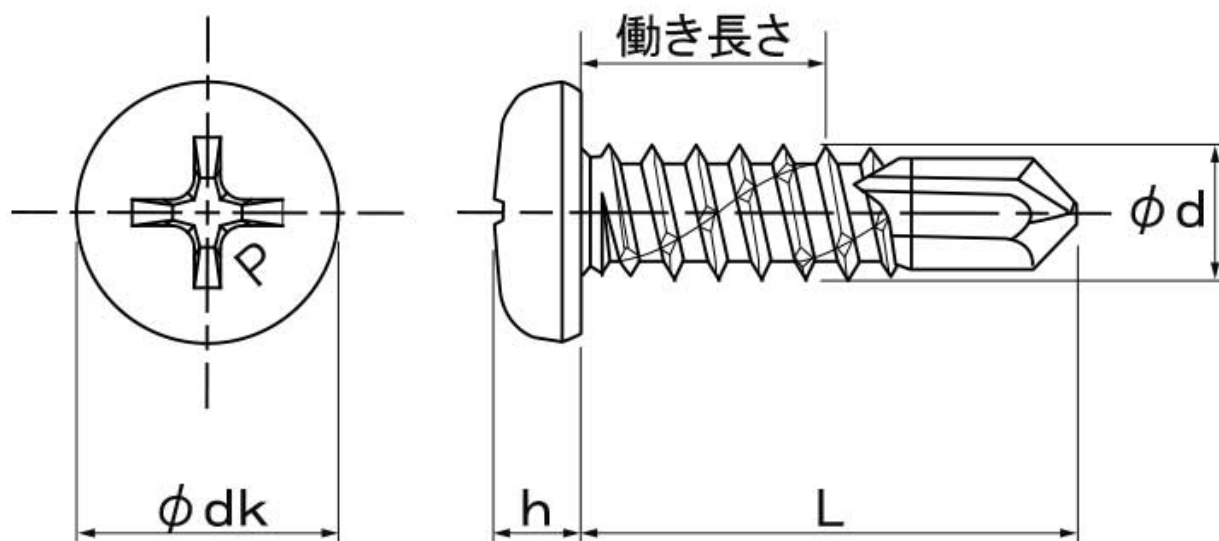

サイズ	L	ねじ部	ϕdk	h	十字穴	ϕd	働き長さ	適応板厚
3X10	10±0.8	金ねじ	5.6	2.2	#1	3	3.5	0.9~1.6
3X13	13±0.8	金ねじ			#1		6.0	0.9~1.6
3X16	16±0.8	金ねじ			#1		9.0	0.9~1.6
3.5X10	10±0.8	金ねじ	7.1	2.9	#2	3.5	3.5	1.2~2.3
3.5X13	13±0.8	金ねじ			#2		6.0	1.2~2.3
3.5X16	16±0.8	金ねじ			#2		9.0	1.2~2.3
3.5X19	19±0.8	金ねじ			#2		12.0	1.2~2.3
3.5X25	25±0.8	金ねじ			#2		18.0	1.2~2.3
4X10	10±0.8	金ねじ	8.2	2.9	#2	4.2	4.0	0.9~2.6
4X13	13±0.8	金ねじ			#2		5.0	1.4~3.2
4X16	16±0.8	金ねじ			#2		8.0	1.4~3.2
4X19	19±0.8	金ねじ			#2		10.0	1.4~3.2
4X25	25±0.8	金ねじ			#2		16.0	1.4~3.2
4X30	30±1.2	金ねじ			#2		21.0	1.4~3.2
4X35X30	35±1.2	30			#2		26.0	1.4~3.2
4X40X30	40±1.2	30			#2		31.0	1.4~3.2
4X45X37	45±1.2	37	#2	36.0	1.4~3.2			
4X50X30	50±1.2	30	#2	41.0	1.4~3.2			

EA949EF-141
EA949EF-142
EA949EF-143
EA949EF-144

サイズ	L	ねじ部	ϕdk	h	十字穴	ϕd	働き長さ	適応板厚
5X13	13±0.8	金ねじ	9.5	3.4	#2	4.8 *1	3.5	1.6~4.0
5X16	16±0.8	金ねじ			#2		6.0	1.6~4.0
5X19	19±0.8	金ねじ			#2		8.0	1.6~4.0
5X25	25±0.8	金ねじ			#2		14.0	1.6~4.0
5X30	30±1.2	金ねじ			#2		19.0	1.6~4.0
5X35	35±1.2	金ねじ			#2		24.0	1.6~4.0
5X40	40±1.2	金ねじ			#2		29.0	1.6~4.0
5X45	45±1.2	金ねじ			#2		34.0	1.6~4.0
5X50X30	50±1.2	30			#2		37.0	1.6~4.0
6X16	16±0.8	金ねじ			10.5		3.9	#3
6X19	19±0.8	金ねじ	#3	7.0		1.8~4.5		
6X25	25±0.8	金ねじ	#3	13.0		1.8~4.5		
6X35	35±1.2	金ねじ	#3	23.0		1.8~4.5		
6X40	40±1.2	金ねじ	#3	25.0		1.8~4.5		
6X45	45±1.2	金ねじ	#3	30.0		1.8~4.5		
6X50X35	50±1.2	35	#3	35.0		1.8~4.5		

EA949EF-151
EA949EF-152
EA949EF-153

*1:SUS410は5.0