
 

 

 








# 合板、根太屋根タルキ 断熱パネル用


材質：鉄鋼線、クロメート

四角RN極太30 (5.8×30)		10		(線材径φ4.0)
四角RN極太40 (5.8×40)		10		(線材径φ4.0)
四角RN極太50 (5.8×50)		10		(線材径φ4.0)
四角RN極太65 (5.8×65)		10		(線材径φ4.0)
四角RN極太75 (5.8×75)		10		(線材径φ4.0)
四角RN極太90 (5.8×90)		10		(線材径φ4.0)

## 四角RN極太ビス 四角-3番

耐震用に安心の極太タイプ  
厚い構造用合板、根太、タルキに最適

根太レス工法に

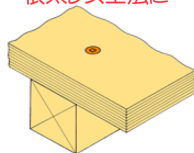

四角RN極太ビス 四角-3番

四角RN外断ビス 四角-3番

(各商品専用ビット1本付き)

EA949FV…〈セット内容〉7点セット

サイズ	(入数)	
5.8×30mm	(70本)	全ねじ
5.8×40mm	(50本)	全ねじ
5.8×50mm	(40本)	全ねじ
5.8×65mm	(40本)	半ねじ
5.8×75mm	(40本)	半ねじ
5.8×90mm	(30本)	半ねじ

EA949FV-30…5.8×30mm	(146本)
EA949FV-40…5.8×40mm	(109本)
EA949FV-50…5.8×50mm	(93本)
EA949FV-65…5.8×65mm	(68本)
EA949FV-75…5.8×75mm	(62本)
EA949FV-90…5.8×90mm	(53本)