


EA949HK-1~-35
(ステンレス製パイプナット)

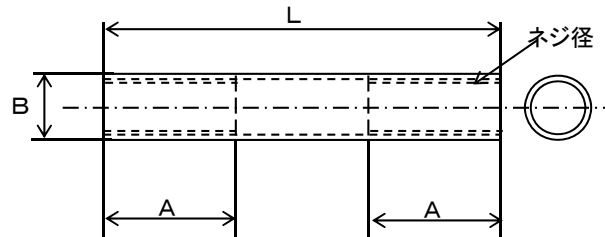

- 材質 SUS304
- 並目

	L	A	B	ネジ径	重さ(g)
EA949HK-1	50	25	8.5	M6	12
EA949HK-2	75	30	8.5	M6	18
EA949HK-3	100	30	8.5	M6	24
EA949HK-4	125	30	8.5	M6	30
EA949HK-5	150	30	8.5	M6	37

	L	A	B	ネジ径	重さ(g)
EA949HK-11	50	25	10	M8	14
EA949HK-12	75	30	10	M8	22
EA949HK-13	100	30	10	M8	30
EA949HK-14	125	30	10	M8	37
EA949HK-15	150	30	10	M8	46

廃番

	L	A	B	ネジ径	重さ(g)
EA949HK-21	50	25	12	M10	18
EA949HK-22	75	30	12	M10	27
EA949HK-23	100	30	12	M10	38
EA949HK-24	125	30	12	M10	49
EA949HK-25	150	30	12	M10	60

廃番

	L	A	B	ネジ径	重さ(g)
EA949HK-31	50	25	17	M12	50
EA949HK-32	75	30	17	M12	75
EA949HK-33	100	30	17	M12	101
EA949HK-34	125	30	17	M12	127
EA949HK-35	150	30	17	M12	154

廃番