



パイプナット

Pipe Nut

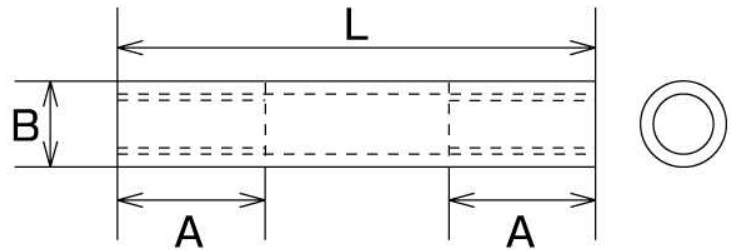


〈使用例〉

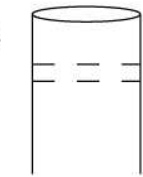

支柱に穴を
開けます。



パイプナットを
通します。

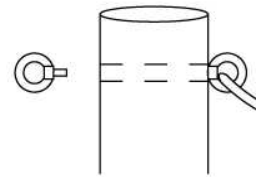

両側からアイボルト
などで固定。

〈ミリネジ〉Metric Thread 材質：ステンレスSUS304

(mm)

品番	L	A	B	捻径	weight (g)	EA品番	コード No.
NC-6M50	50	25	8.5	M-6	12	EA949HK-1	1561
NC-6M75	75	30			18	EA949HK-2	1562
NC-6M100	100				24	EA949HK-3	1563
NC-6M125	125				30	EA949HK-4	1564
NC-6M150	150				37	EA949HK-5	1565
NC-8M50	50	25	10	M-8	14	EA949HK-11	1566
NC-8M75	75	30			22	EA949HK-12	1567
NC-8M100	100				30	EA949HK-13	1568
NC-8M125	125				37	EA949HK-14	1569
NC-8M150	150				46	EA949HK-15	1570
NC-10M50	50	25	12	M-10	18	EA949HK-21	1571
NC-10M75	75	30			27	EA949HK-22	1572
NC-10M100	100				38	EA949HK-23	1573
NC-10M125	125				49	EA949HK-24	1574
NC-10M150	150				60	EA949HK-25	1575
NC-12M50	50	25	17	M-12	50	EA949HK-31	1576
NC-12M75	75	30			75	EA949HK-32	1577
NC-12M100	100				101	EA949HK-33	1578
NC-12M125	125				127	EA949HK-34	1579
NC-12M150	150				154	EA949HK-35	1580

※左右とも右ネジです。