

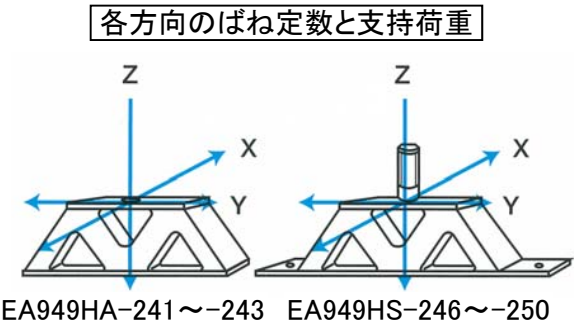


EA949HS-241~EA949HS-250 山形防振ゴム

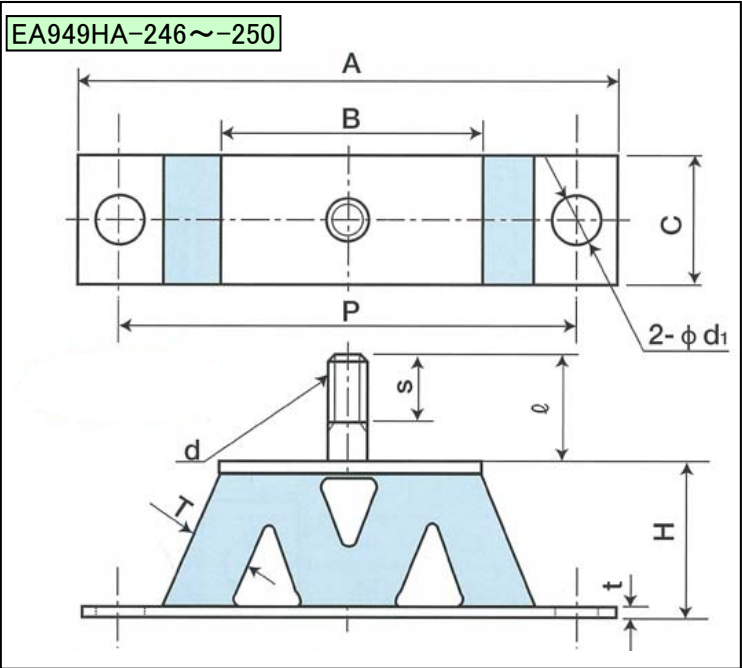

- ゴム材質…天然ゴム
- 耐久性、耐低温性、反発弾性に優れています。
- 計器盤、発電機、ポンプ、汎用機械などの防振対策に最適です。

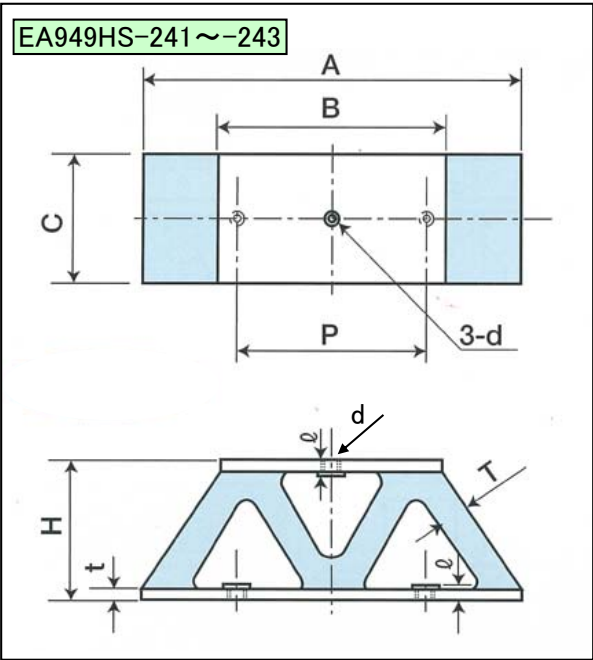

品番	穴/ねじ	サイズ(mm)										重量 (g)	ばね定数(N/mm)			支持荷重(N)		
	d	H	A	B	C	P	ℓ	S	t	d1	T		Z方向	Y方向	X方向	Z方向	Y方向	X方向
EA949HS-241	4mm	22	60	35	20	30	3.5	-	1.6	-	5	40	34	18	10	49	29	9
EA949HS-242											6.5	80	54	22	14	98	39	29
EA949HS-243											8	100	79	24	16	195	58	39
EA949HS-246	M8	30	100	40	25	84	24	21	3.2	9	8	140	98	29	20	290	88	58
EA949HS-247	M10	40	125	55	30	104	30	25	4.5	11	12	280	165	49	33	580	175	115
EA949HS-248	M12	45	160	70	35	130	36	31		14.5	17	440	245	49	49	980	195	195
EA949HS-249	M16	55	210	90	40	170	48	43	6	17.5	20	795	275	55	55	1750	350	350
EA949HS-250		65	245	115	50	205			8	20	30	1600	440	88	88	2900	585	585

廃番