


図面／規格
【六角ナット（１種鉄M 2 5 以上黒皮）】

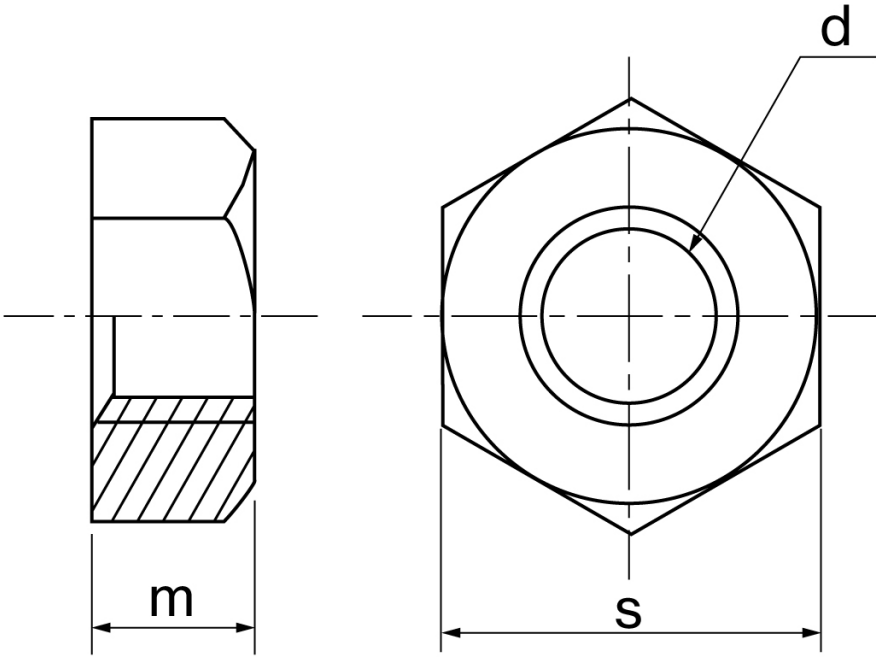

EA949JE- シリーズ

	呼び	並目	m		s	
			基準寸法	許容差	基準寸法	許容差
	M2	0.4	1.6	0 -0.25	4	0 -0.2
	M2.3	0.4	1.8		4.5	
	M2.5	0.45	2		5	
	M2.6	0.45	2		5	
	M3	0.5	2.4		5.5	
	M3.5	0.6	2.8	0 -0.30	6	0 -0.25
	M4	0.7	3.2		7	
	M4.5	0.75	3.6		8	
	M5	0.8	4		8	
-6	M6	1.0	5		10	
	M7	1.0	5.5	0 -0.58	11	0 -0.7
-8	M8	1.25	6.5		13	
	M9	1.25	8		17	
-10	M10	1.5	8	±0.8	17	0 -0.8
-12	M12	1.75	10		19	
-14	M14	2.0	11		22	
-16	M16	2.0	13	±0.9	24	0 -1.4
-18	M18	2.5	15		27	

	呼び	並目	m		s	
			基準寸法	許容差	基準寸法	許容差
-20	M20	2.5	16	±0.9	30	0 -0.8
-22	M22	2.5	18		32	
-24	M24	3.0	19	±1.0	36	0 -1.0
	M25	3.0	19		36	
-27	M27	3.0	22		41	
-30	M30	3.5	24		46	
-33	M33	3.5	26		50	
-36	M36	4.0	29	±1.2	55	0 -1.2
-39	M39	4.0	31		60	
-42	M42	4.5	34		65	
	M45	4.5	36		70	
	M48	5.0	38		75	
	M52	5.0	42	±1.5	80	0 -1.4
	M56	5.5	45		85	
	M60	5.5	48		90	
	M64	6.0	51		95	
	M68	6.0	54		100	