


図面／規格
【六角ナット（１種鉄M 2 5 以上黒皮）】

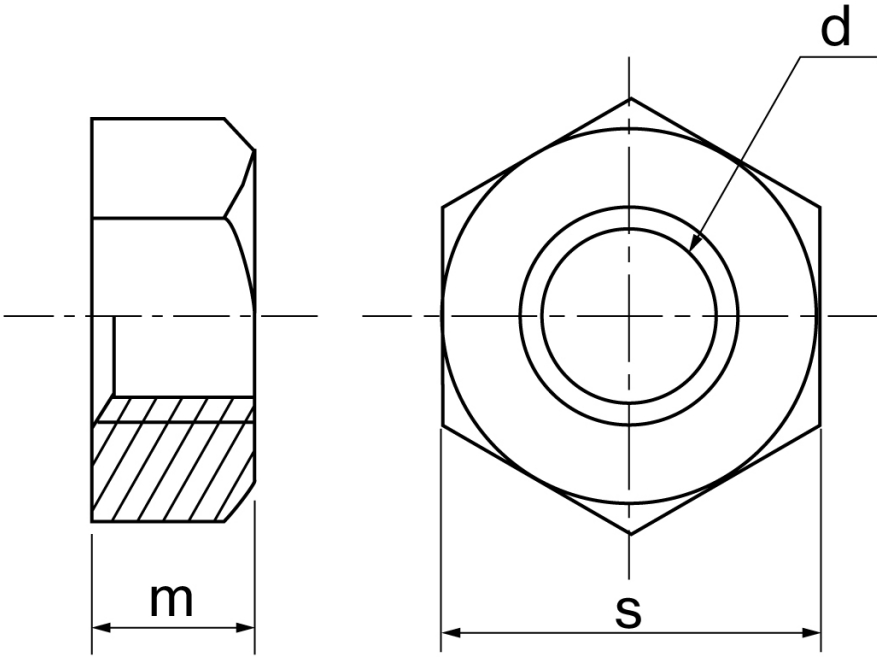

EA949JF- シリーズ

呼び	並目	m		s	
		基準寸法	許容差	基準寸法	許容差
M2	0.4	1.6	0 -0.25	4	0 -0.2
M2.3	0.4	1.8		4.5	
M2.5	0.45	2		5	
M2.6	0.45	2		5	
M3	0.5	2.4		5.5	
M3.5	0.6	2.8	0 -0.30	6	0 -0.25
M4	0.7	3.2		7	
M4.5	0.75	3.6		8	
M5	0.8	4		8	
M6	1.0	5		10	
M7	1.0	5.5	0 -0.58	11	0 -0.7
M8	1.25	6.5		13	
M9	1.25	8		17	
M10	1.5	8	±0.8	17	0 -0.8
M12	1.75	10		19	
M14	2.0	11	±0.9	22	0 -0.8
M16	2.0	13		24	
M18	2.5	15		27	

呼び	並目	m		s	
		基準寸法	許容差	基準寸法	許容差
M20	2.5	16	±0.9	30	0 -0.8
M22	2.5	18		32	0 -1.0
M24	3.0	19	±1.0	36	
M25	3.0	19		36	
M27	3.0	22		41	
M30	3.5	24		46	
M33	3.5	26	±1.2	50	0 -1.2
M36	4.0	29		55	
M39	4.0	31		60	
M42	4.5	34		65	
M45	4.5	36		70	
M48	5.0	38	±1.5	75	0 -1.4
M52	5.0	42		80	
M56	5.5	45		85	
M60	5.5	48		90	
M64	6.0	51		95	
M68	6.0	54		100	