


EA949K - 55 ~ - 100  
 ファインUナット用ソケットレンチ

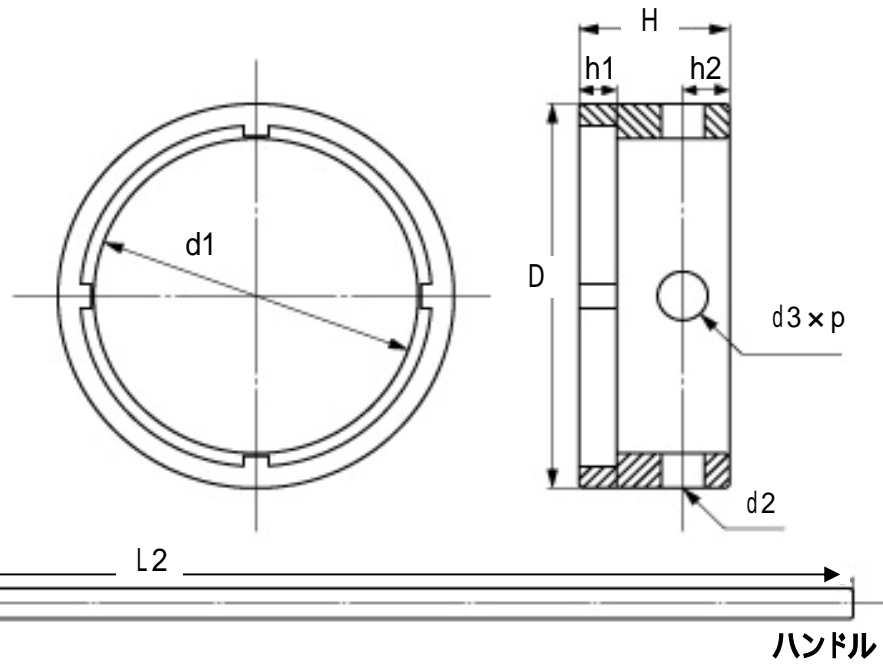

品番	呼び	適用ナットサイズ	ソケット							ハンドル
			D	d1	H	h1	h2	d2	d3 × p	d4 × L2
EA949K-55	11	M55 × 2	85.6	69	36	8.5	11	12	M12 × 1.75	12 × 500
EA949K-60	12	M60 × 2	91.0	74						
EA949K-65	13	M65 × 2	96.5	79	41	9.5	13	14	M14 × 2.0	14 × 650
EA949K-70	14	M70 × 2	104.0	85						
EA949K-75	15	M75 × 2	110.5	90.5						
EA949K-80	16	M80 × 2	118.0	97.5	44	12.5	15	16	M16 × 2.0	16 × 750
EA949K-85	17	M85 × 2	123.5	102.5						
EA949K-90	18	M90 × 2	134.0	111	50	13	15	16	M16 × 2.0	16 × 750
EA949K-95	19	M95 × 2	139.5	116						
EA949K-100	20	M100 × 2	145.0	121	52	15				

単位: mm