


図面／規格
【六角ナット（UNC）】

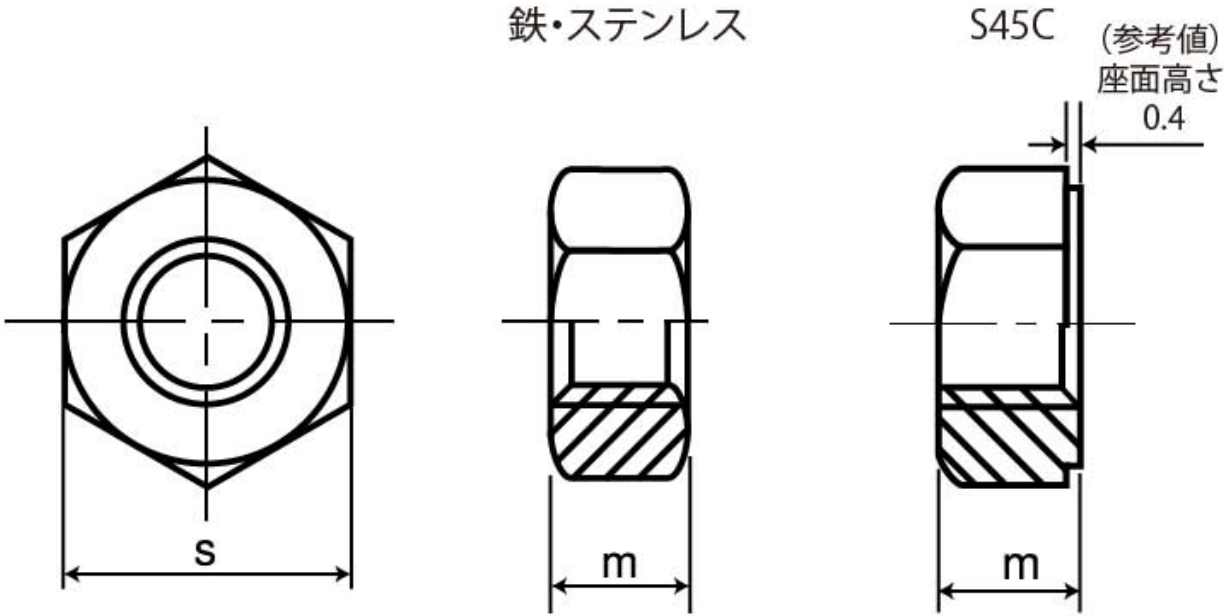

EA949LT-51 ~ -63

●鉄・ステンレス

	呼び径 d	二面幅 s		高さ m
		基準 寸法	スパナ サイズ	
	#1-64	3.97	5/32	1.27
-51	#2-56	4.77	3/16	1.67
	#3-48	4.77	3/16	1.67
-52	#4-40	6.35	1/4	2.48
	#5-40	8	5/16	2.8
-53	#6-32	8	5/16	2.8
-54	#8-32	8.73	11/32	3.30
-55	#10-24	9.5	3/8	3.3
	#12-24	11.11	7/16	4.08
-56	1/4-20	11.13	7/16	5.74
-57	5/16-18	12.70	1/2	6.93
-58	3/8-16	14.27	9/16	8.56
	7/16-14	17.48	11/16	9.78
-59	1/2-13	19.05	3/4	11.38
	9/16-12	22.23	7/8	12.60
-60	5/8-11	23.83	15/16	14.20
-61	3/4-10	28.58	1-1/8	16.89
-62	7/8-9	33.32	1-5/16	19.71
-63	1"-8	38.10	1-1/2	22.53
	1"1/8-7	42.88	1-11/16	25.37
	1"1/4-7	47.63	1-7/8	27.79

●S45C

呼び径 d	二面幅 s		高さ m	※座面高さ (参考)
	基準 寸法	スパナ サイズ	基準 寸法	基準寸法
1/4-20	11.13	7/16	5.74	0.4
5/16-18	12.70	1/2	6.93	0.4
3/8-16	14.27	9/16	8.56	0.4
7/16-14	17.48	11/16	9.78	0.4
1/2-13	19.05	3/4	11.38	0.4
5/8-11	23.83	15/16	14.20	0.4
3/4-10	28.58	1-1/8	16.89	0.4
7/8-9	33.32	1-5/16	19.71	0.4
1"-8	38.10	1-1/2	22.53	0.4
1"1/4-7	47.63	1-7/8	27.79	0.4

※S45Cのみ座付きになります