


図面／規格  
【CAP（細目）】

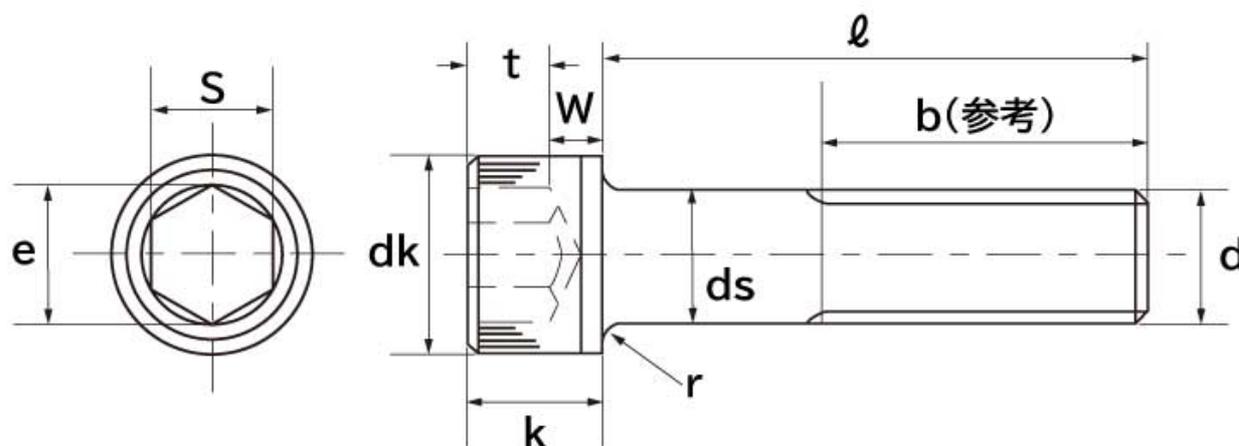

## EA949LZ- シリーズ

-61~66  
-81~85  
-101~110  
-121~128

ねじの 呼び	ピッチ	※b 参考	dk			ds		e 最小	k		s 呼び	t 最小	w 最小
			最大 (基準寸法)	最大	最小	最大	最小		最大	最小			
M3	0.35	18	5.50	5.68	5.32	3.00	2.86	2.873	3.00	2.86	2.5	1.3	1.15
M4	0.5	20	7.00	7.22	6.78	4.00	3.82	3.443	4.00	3.82	3	2	1.4
M5	0.5	22	8.50	8.72	8.28	5.00	4.82	4.583	5.00	4.82	4	2.5	1.9
M6	0.75	24	10.00	10.22	9.78	6.00	5.82	5.723	6.0	5.7	5	3	2.3
M8	1.0	28	13.00	13.27	12.73	8.00	7.78	6.863	8.00	7.64	6	4	3.3
M10	1.25	32	16.00	16.27	15.73	10.00	9.78	9.149	10.00	9.64	8	5	4
M12	1.25	36	18.00	18.27	17.73	12.00	11.73	11.429	12.00	11.57	10	6	4.8
M14	1.5	40	21.00	21.33	20.67	14.00	13.73	13.716	14.00	13.57	12	7	5.8
M16	1.5	44	24.00	24.33	23.67	16.00	15.73	15.996	16.00	15.57	14	8	6.8
M18	1.5	48	27	27.33	26.67	18	17.73	16.00	18	17.57	14	9	7.7
M20	1.5	52	30.00	30.33	29.67	20.00	19.67	19.437	20.00	19.48	17	10	8.6
M22	1.5	56	33	33.39	32.61	22	21.67	19.44	22	21.48	17	11	9.5
M24	2.0	60	36.00	36.39	35.61	24.00	23.67	21.734	24.00	23.48	19	12	10.4
M27	2.0	66	40	40.39	39.61	27	26.67	21.73	27	26.48	19	13.5	12.1
M30	2.0	72	45.00	45.39	44.61	30.00	29.67	25.154	30.00	29.48	22	15.5	13.1
M33	2.0	78	50	50.39	49.61	33	32.61	27.43	33	32.38	24	16.5	15.0
M36	3.0	84	54.00	54.46	53.54	36.00	35.61	30.854	36.00	35.38	27	19	15.3
M42	3.0	96	63.00	63.46	62.54	42.00	41.61	36.571	42.00	41.38	32	24	16.3
M48	3.0	108	72.00	72.46	71.54	48.00	47.61	41.131	48.00	47.38	36	28	17.5