


図面／規格
【（＋）皿小ねじ（全ねじ）】

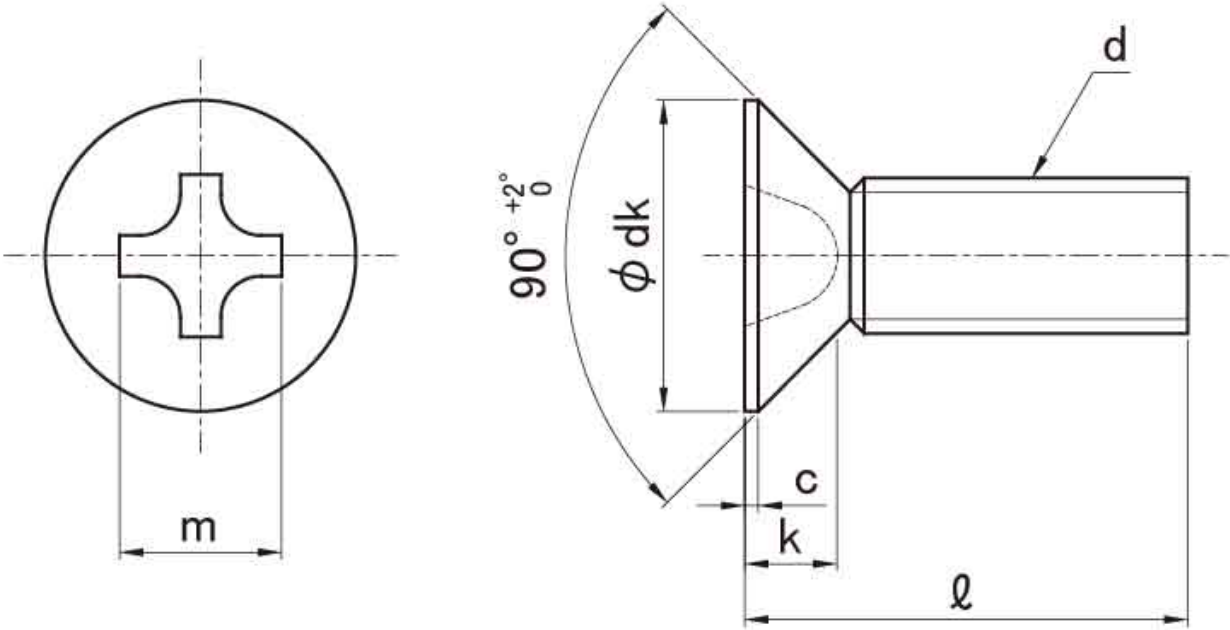

ねじの 呼び d	ピッチ	十字穴 の番号	dk		k		C (約)
			基準 寸法	許容差	基準 寸法	許容差	
EA949NU-200 ~ -206	M2	0.4	4	0 -0.4	1.2	0 -0.2	0.2
EA949NU-230 ~ -234	M2.3	0.4	4.6		1.35		0.2
	M2.5	0.45	5		1.45		0.2
EA949NU-260 ~ -267	M2.6	0.45	5.2		1.5		0.2
EA949NU-300 ~ -304	M3	0.5	6	0 -0.5	1.75	0 -0.3	0.25
	M3.5	0.6	7		2		0.25
	M4	0.7	8		2.3		0.3
EA949NU-400 ~ -405	M4.5	0.75	9	0	2.55		0.3
	M5	0.8	10	-0.6	2.8		0.3
	M6	1.0	12	0 -0.7	3.4	0 -0.4	0.4
	M8	1.25	16	0 -0.8	4.4		0.4
	M10	1.5	20	0 -1.3	5.7	0	0.7
	M12	1.75	24		6.7	-0.5	0.5
	M16	2.0	30		7.7	0 -0.3	-