


[ステンレス製]穴用スナップリング
EA949PA-306~324

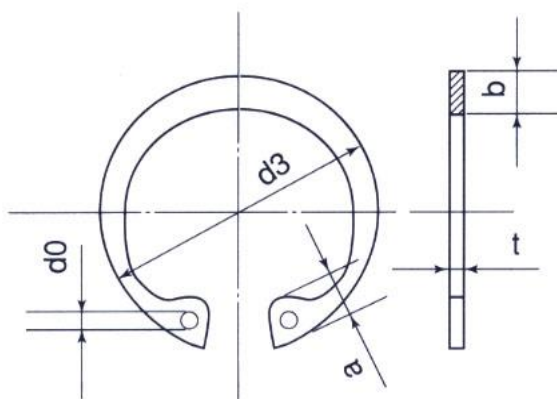

●材質…ステンレス

品番	適合穴径 (mm)	サイズ(mm)					入数 (1個)	重量(g) (1個)
		d3	t	b	a	d0		
EA949PA-306	6.4	6.70	0.40	0.70	1.60	0.80	15	0.03
EA949PA-308	8	8.80	0.40	0.90	1.70	0.80		0.05
EA949PA-309	9.5	9.80	0.60	1.10	2.20	0.80	13	0.12
EA949PA-310	10	10.70	1.00	1.50	2.80	1.20	12	0.28
EA949PA-311	11	11.80	1.00	1.50	3.00	1.20		0.34
EA949PA-312	12	13.00	1.00	1.70	3.10	1.50	11	0.36
EA949PA-313	13	14.10	1.00	1.70	3.10	1.50		0.46
EA949PA-314	14	15.10	1.00	1.90	3.60	1.50		0.45
EA949PA-315	15	16.20	1.00	1.90	3.60	1.70		0.49
EA949PA-316	16	17.30	1.00	1.90	3.70	1.70	10	0.59
EA949PA-317	17	18.30	1.00	1.90	3.80	1.70	9	0.64
EA949PA-318	18	19.50	1.00	2.40	4.00	1.70		0.71
EA949PA-319	19	20.50	1.00	2.50	4.00	2.00	8	0.80
EA949PA-320	20	21.50	1.00	2.50	4.00	2.00		0.85
EA949PA-321	21	22.50	1.00	2.50	4.10	2.00	7	0.94
EA949PA-322	22	23.50	1.00	2.50	4.10	2.00		0.93
EA949PA-323	23	24.70	1.00	2.50	4.10	2.00	6	1.33
EA949PA-324	24	25.90	1.20	2.50	4.30	2.00		1.32