


[ステンレス製]軸用スナップリング  
EA949PA-403~-424



403~408




409~424

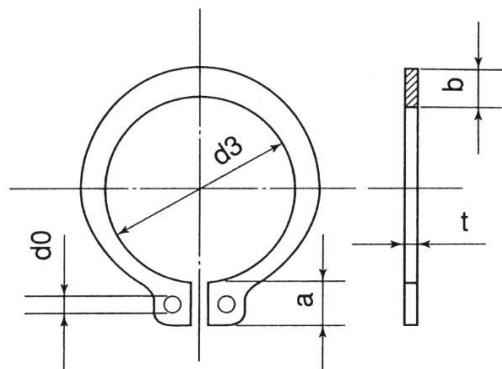

●材質…ステンレス

品番	適合軸径 (mm)	サイズ(mm)					入数	重量(g) (1個)
		d3	t	b	a	d0		
EA949PA-403	3	2.7	0.25	0.50	1.70	0.70	22	0.010
EA949PA-404	4	3.7	0.40	0.90	2.20	0.80	21	0.017
EA949PA-405	5	4.7	0.60	1.10	2.40	0.80	20	0.033
EA949PA-406	6	5.6	0.70	1.30	2.80	1.00	19	0.056
EA949PA-407	7	6.5	0.80	1.40	3.00	1.00	17	0.098
EA949PA-408	8	7.4	0.80	1.60	3.00	1.00	16	0.127
EA949PA-409	9	8.4	1.00	1.80	3.20	1.00	15	0.146
EA949PA-410	10	9.3	1.00	1.80	3.00	1.20	12	0.371
EA949PA-411	11	10.2	1.00	2.00	3.10	1.20		0.477
EA949PA-412	12	11.1	1.00	2.10	3.20	1.50	11	0.475
EA949PA-413	13	12.0	1.00	2.10	3.30	1.50		0.600
EA949PA-414	14	12.9	1.00	2.20	3.40	1.70	10	0.672
EA949PA-415	15	13.8	1.00	2.20	3.50	1.70		0.670
EA949PA-416	16	14.7	1.00	2.20	3.60	1.70	9	0.755
EA949PA-417	17	15.7	1.00	2.20	3.70	1.70		0.812
EA949PA-418	18	16.5	1.20	2.60	3.80	1.70	8	1.207
EA949PA-419	19	17.5	1.20	2.70	3.80	2.00	7	1.271
EA949PA-420	20	18.5	1.20	2.70	3.90	2.00		1.324
EA949PA-421	21	19.5	1.20	2.70	4.00	2.00	6	1.377
EA949PA-422	22	20.5	1.20	2.70	4.10	2.00		1.426
EA949PA-423	23	21.4	1.20	2.90	4.50	2.00		1.537
EA949PA-424	24	22.2	1.20	3.10	4.20	2.00	5	1.803

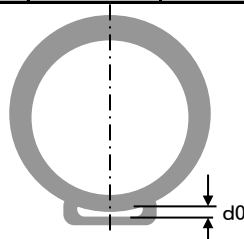

EA949PA-403~-408はこの形状になります。